

[Labels](#) / [Labels by Application](#) / [Barcode Labels](#) /

3" Core Series WorkHorse Glossy Polyester Labels

3" Core Series WorkHorse Glossy Polyester Labels



Product Highlights:

Label/Tape Size:

1.25 in H x 2.75 in W

Material:

Polyester

For Use with Printer:

BBP®81 Label Printer, BRADY IP® Series

Label Printer, BradyPrinter i5100,

BradyPrinter i7100, BRADYPRINTER PR

Plus Series Label Printer, THT 3" Core

Printer

Part Number:

THT-7-423-3

[ADD TO CART](#)

1

[Add To Favorites](#)

Need a different size? Customize it!

PEOPLE WHO VIEWED THIS ITEM ULTIMATELY BOUGHT

OVERVIEW

Permanent Polyester (B-423) is ideal for electronic PCB and component identification, bar code labels, rating plates and solar panel identification.

- Glossy white finish with permanent acrylic is thermal transfer printable
- RoHS compliant to 2005/618/EC MCV amendment to RoHS Directive 2002/95/EC; UL approved; CSA accepted
- Meets requirements of a halogen-free material per DIN VDE 0472 part 815
- Service temperature of -94 to 230° F (-70 to 110° C)

SPECIFICATIONS

Material Number	B-423
Catalog Page #	154
Dimensions	1.25 in H x 2.75 in W
UOM	Roll of 3000 Labels
Finish	Gloss
Indoor or Outdoor Use	Outdoor Use
Label/Tape Size	1.25 in H x 2.75 in W
Maximum Service Temperature °F	230 °F
Minimum Service Temperature °F	-94 °F
Printable Area Dimensions	1.25 in H x 2.75 in W
Printable Area Height	1.25 in
Printable Area Width	2.75 in
Product Number	30118
UPC	662820301189
Quantity per Roll	3000
Quantity per Row	1
Secondary Label Included	Secondary Label is Not Included
Thickness	0.003 in
Trade Name	WorkHorse® ToughBond®
Unit Price	/Label
Adhesive Type	Acrylic
Applications	Asset Tracking, Barcode Labeling, Circuit Board ID - Through Hole Top, Component & Equipment ID, General & Industrial ID, Rating Plates
Color	White
For Use with Printer	BBP®81 Label Printer, BRADY IP® Series Label Printer, BradyPrinter i5100, BradyPrinter i7100, BRADYPRINTER PR Plus Series Label Printer, THT 3" Core Printer
Label/Media Format	Roll
Label Properties	Aggressive Adhesive Labels, Harsh Environment Labels, Heat Resistant Labels, Permanent Adhesive Labels
Material	Polyester
Print Technology	Thermal Transfer
Resistance Properties	Abrasion-Resistant, Chemical-Resistant, Corrosion-Resistant, Humidity-Resistant, UV-Resistant, Weather-Resistant
Shape	Rectangle

Solutions

- Floor Marking Guide
- GHS Label Compliance
- Lockout Tagout Compliance
- Arc Flash Labeling Requirements
- Cable and Wire Label Options
- Product and Barcode Labeling
- Brand Protection Solutions

Services

- Lockout Tagout Services
- Arc Flash Services
- Confined Space Services
- Software Programming & Integration
- Label Template & File Conversion
- Printer Use & Training
- Printer Preventative Maintenance
- Toll and Custom Coating
- Authentication & Tracking Services

Help

- Contact Us
- Website Feedback
- Knowledge Center
- Printer Drivers & Firmware
- Brady Software Updates
- Safety Data Sheets
- Technical Data Sheets
- WEEE-RoHS Compliance
- Product Certification
- Printer Registration

Resources

- Find a Distributor
- Design Custom Safety Signs
- Printer Selection Tool
- Label Selection Tool
- Digital Catalog
- Request a Catalog
- Interactive Facility Map
- EPA e-Manifest Update

Corporate

[About](#)

[Careers](#)

[Investors](#)

[Privacy Policy](#)

[Terms and Conditions](#)

[Terms of Use](#)

[ISO](#)

[Certificates](#)

Other Brady

[Distributor Portal](#)

[International Sites](#)

[Safety Services & Software](#)

[Smart ID Brand](#)

[Protection Solutions](#)


Contact

6555 W. Good Hope Rd. Milwaukee, WI 53223

Phone: 888-250-3082

Hours: 7am-6pm CT Monday - Thursday; Friday 7am-5pm CT

Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.

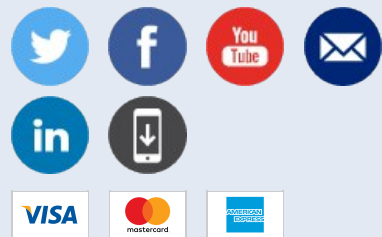

2018 © Brady Worldwide, Inc.