



Part Number : [1300940384](#)


Product Description : Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 88.90-101.35m (3.500-3.990"), Approximate Break Strength 2394.97kg (5280 lbs)

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Number : 35280

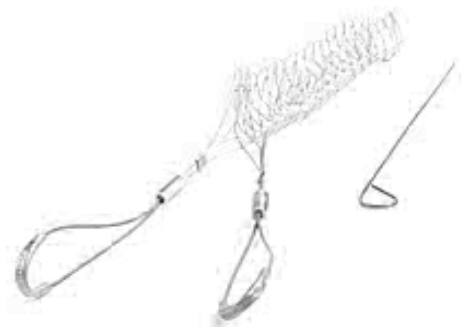

Documents & Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 88.90-101.35m (3.500-3.990"), Approximate Break Strength 2394.97kg (5280 lbs)
Product Name	Standard Duty
Type	Support Grip
UPC	78678835280

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	2394.97kg (5280 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	88.90-101.35mm (3.500-3.990")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.711m (28.00")
Number of Holes	N/A
O-Ring	N/A
Thread Size	N/A

This document was generated on Sep 18, 2025