



Connector Location A

Connector Location B

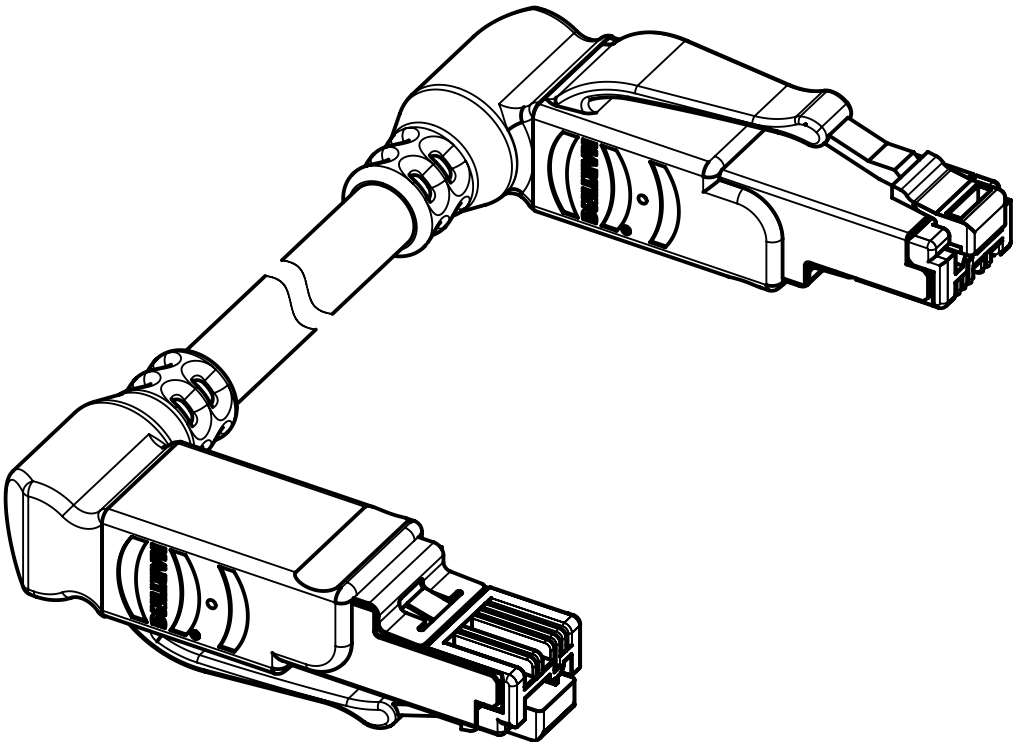

X
male



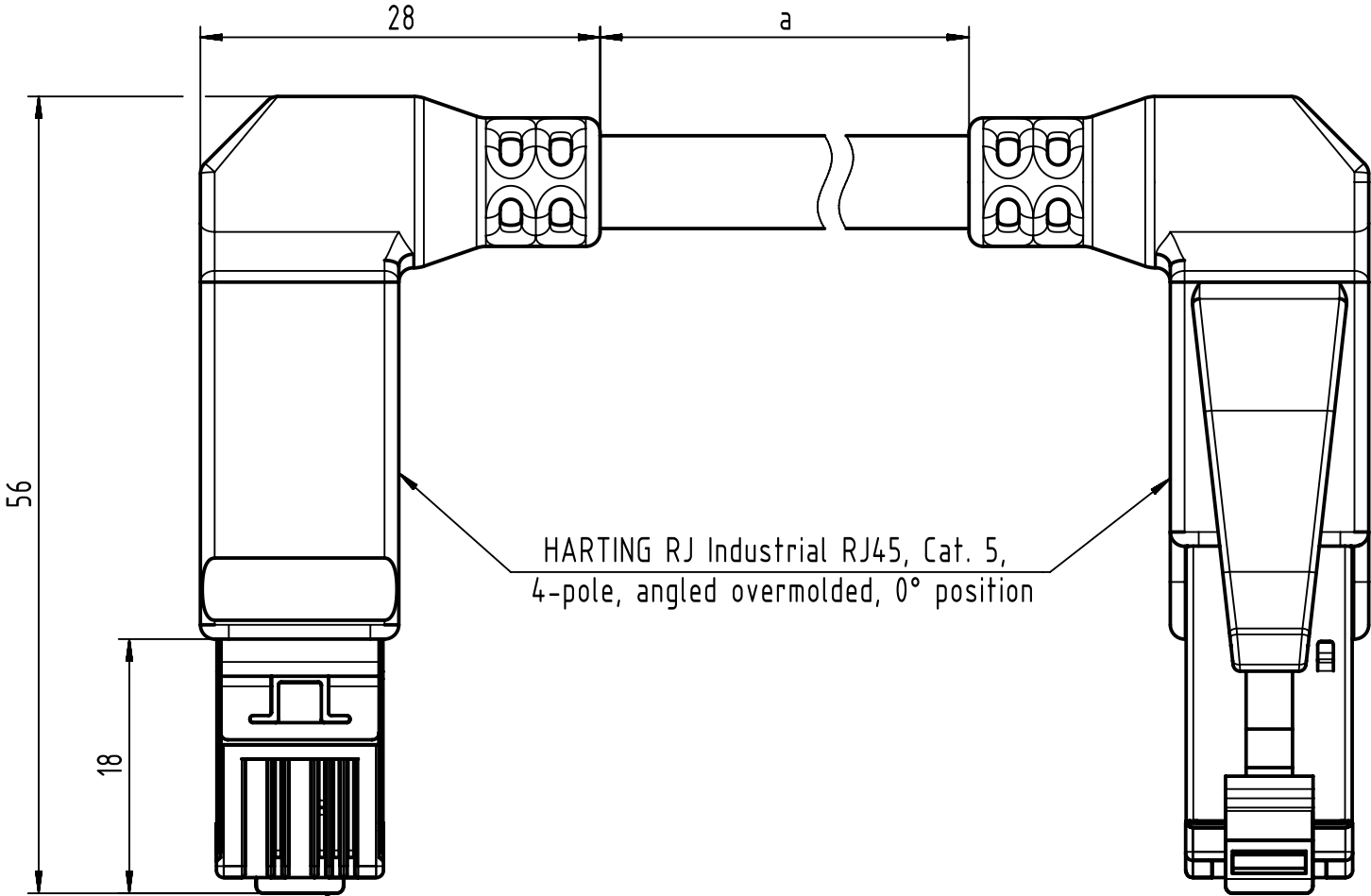


Y
male

HARTING RJ Industrial RJ45, Cat. 5,
4-pole, angled overmolded, 0° position

Mating face RJ45 acc. to IEC 60603-7

Loading Plan

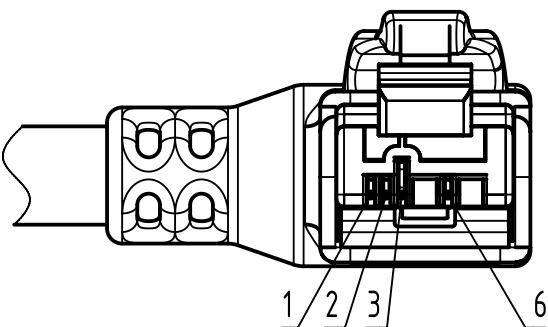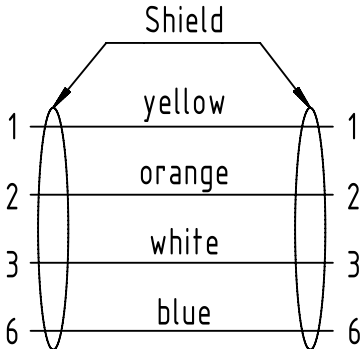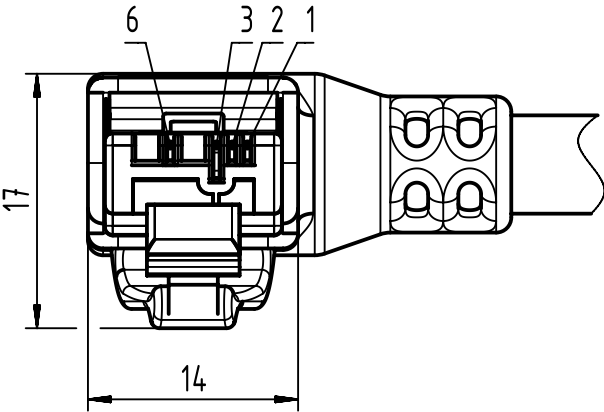

- Protection level: IP20
- Temperature range: -40°C ... +70°C

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
	All rights reserved	Created by BANIUD Banciu	Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2019-08-08	State Final Release	
	Department HCS - RO	Title RJ Industrial Cable Assembly				Doc-Key / ECM-Nr. 100155467/UGD/004/E 500000156257	
	HARTING Customised Solutions D-32339 Espelkamp	Type TB	Number 09457714XXX			Rev. E	Page 1/2

	1	2	3	4	5	6	7	8
A					RJl Ethernet Trailing Cable, 4xAWG 22/7, PUR, Cat. 5+, green			
B	RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC outdoor, Cat. 5+, black				RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC, Cat. 5+, green			
C								
D								
E	RJl Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green							
F								

44	09457714083		100
43	09457714082		90
42	09457714081		80
41	09457714080		70
40	09457714079		60
39	09457714078		50
38	09457714077		40
37	09457714076		30
36	09457714075		20
35	09457714074		15
34	09457714073		10
33	09457714072		9
32	09457714071		8
31	09457714070		7
30	09457714069		6
29	09457714068		5
28	09457714067		4
27	09457714066		3
26	09457714065		2
25	09457714064		1.5
24	09457714063		1
23	09457714062		0.5
22	09457714061		100
21	09457714060		90
20	09457714059		80
19	09457714058		70
18	09457714057		60
17	09457714056		50
16	09457714055		40
15	09457714054		30
14	09457714053		20
13	09457714052		15
12	09457714051		10
11	09457714031		9
10	09457714030		8
9	09457714029		7
8	09457714028		6
7	09457714027		5
6	09457714026		4
5	09457714025		3
4	09457714024		2
3	09457714023		1.5
2	09457714022		1
1	09457714021		0.5
Cont. no.	Part no.	Type of cable	Dim. a[m]

88	09457714183		100
87	09457714182		90
86	09457714181		80
85	09457714180		70
84	09457714179		60
83	09457714178		50
82	09457714177		40
81	09457714176		30
80	09457714175		20
79	09457714174		15
78	09457714173		10
77	09457714172		9
76	09457714171		8
75	09457714170		7
74	09457714169		6
73	09457714168		5
72	09457714167		4
71	09457714166		3
70	09457714165		2
69	09457714164		1.5
68	09457714163		1
67	09457714162		0.5
66	09457714161		100
65	09457714160		90
64	09457714159		80
63	09457714158		70
62	09457714157		60
61	09457714156		50
60	09457714155		40
59	09457714154		30
58	09457714153		20
57	09457714152		15
56	09457714151		10
55	09457714131		9
54	09457714130		8
53	09457714129		7
52	09457714128		6
51	09457714127		5
50	09457714126		4
49	09457714125		3
48	09457714124		2
47	09457714123		1.5
46	09457714122		1
45	09457714121		0.5
Cont. no.	Part no.	Type of cable	Dim. a[m]

		Tech. Character.		Free size tol.		According to production drawing	
All Dimensions in mm							
		All rights reserved		Created by BANCIUD Banciu	Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2019-08-08
Department HCS - RO		Title RJ Industrial Cable Assembly		State Final Release		Doc-Key / ECM-Nr. 100155467/UGD/004/E 500000156257	
HARTING Customised Solutions D-32339 Espelkamp		Type TB	Number 09457714XXX		Rev. E	Page 2/2	