


Data Sheet | Item Number: 282-365

End and separator plate; for 2-conductor longitudinal switching disconnect terminal block; 1.5 mm thick; orange

<https://www.wago.com/282-365>

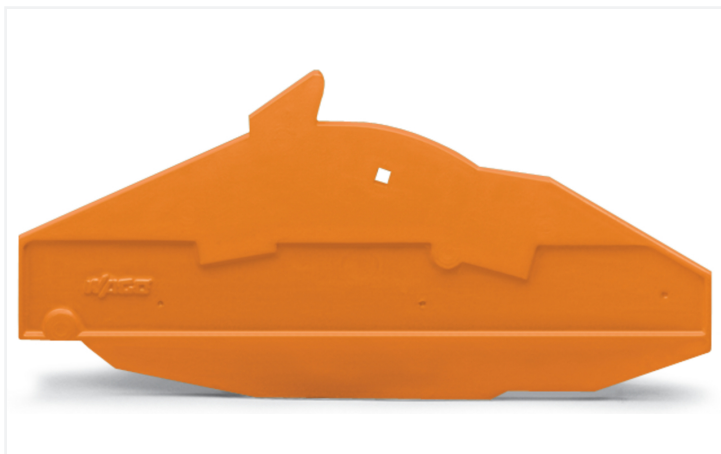

Color: ■ orange

Physical data

Width	1.5 mm / 0.059 inches
Height	98 mm / 3.858 inches
Depth	46.5 mm / 1.831 inches

Material data

Note (material data)	Information on material specifications can be found here
Color	orange
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.088 MJ
Weight	2.9 g

Environmental requirements

Processing temperature	-35 ... +85 °C
Continuous operating temperature	-60 ... +105 °C

Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)
PU (SPU)	50 (10) pcs
Packaging type	Box
Country of origin	CN
GTIN	4017332813037
Customs tariff number	85389099990



Product Classification	
UNSPSC	39121410
eCl@ss 10.0	27-14-11-33
eCl@ss 9.0	27-14-11-33
ETIM 9.0	EC000886
ETIM 10.0	EC000886
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads	
Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 282-365	↓

Documentation			
Bid Text			
282-365	19.02.2019	xml 2.62 KB	↓
282-365	03.03.2017	doc 23.50 KB	↓

CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 282-365 ↓	EPLAN Data Portal 282-365 ↓
	WSCAD Universe 282-365 ↓
	ZUKEN Portal 282-365 ↓

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com