



6 LED FESTOON LAMP

FEATURES

Non-Polarized
 12V and 24V AC and DC Operation
 High Efficacy - 90 Lm/Watt Cool White
 86 Lm/Watt Neutral White
 80 Lm/Watt Warm White
 Standard Size - Fits JKL Socket #2910F-47

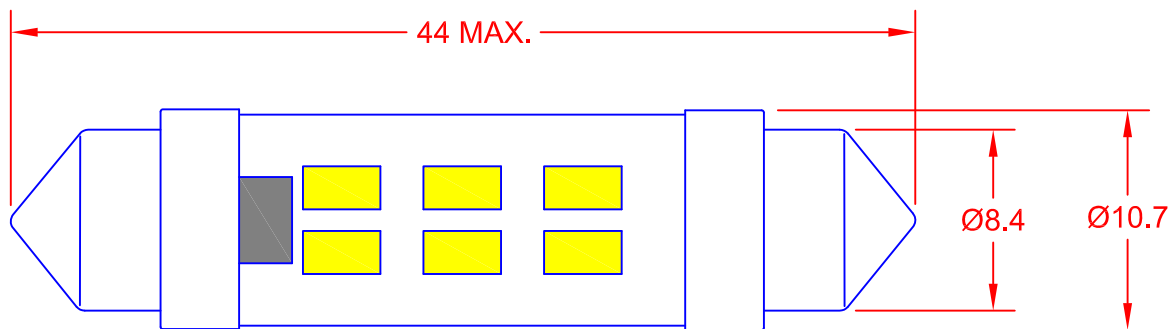

JKL PART NUMBER	Color	Input Voltage (V AC/DC)			Power Typ. (W)	Current Typ. (mA)	Radiance Angle (Deg.)	CCT(K)	Lumen Flux (lm)	Operating Temp. (deg. C)		
		Min.	Typ.	Max.						Min.	Typ.	Max.
LE-0909-14CW	Cool White	--	12	24	0.5	45	120	6000	45	-20	25	40
LE-0909-14NW	Neutral White	--	12	24	0.5	45	120	4500	43	-20	25	40
LE-0909-14WW	Warm White	--	12	24	0.5	45	120	3000	40	-20	25	40

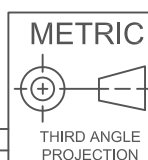

METRIC
 DIMENSIONS ARE
 IN MILLIMETERS
 TOLERANCE UNLESS
 OTHERWISE SPECIFIED
 1 PL +/- 0.5
 2 PL +/- 0
 ANGLE +/- 0

JKL COMPONENTS CORPORATION

TITLE

6 LED FESTOON LAMP

DRAWN BY
 L. WENGSTROM

APP'D BY DATE
 L.R. 11/11/13

SIZE
A

FSCM NO.
55335

DRAWING
 NO. LE-0909-14

- CAD DRAWING -
 MANUAL REVISIONS NOT PERMITTED

SCALE
 NONE

RELEASED
 DATE 6/20/11

REVISION
 DATE 11/11/13

REV.
 NO. **A** SHEET
 1 OF 1