

SEK CAB FLAT SH RND AWG28/7 14P 30,48m

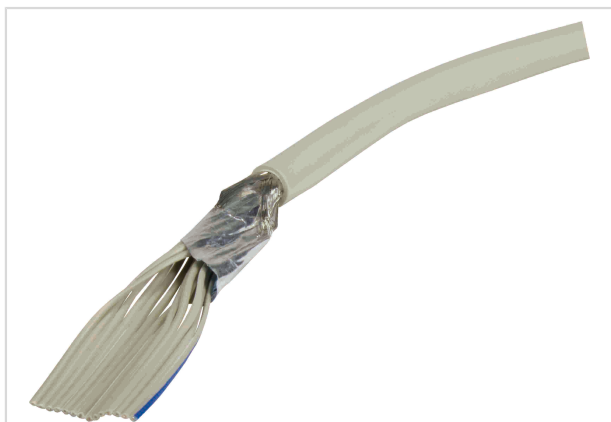


Image is for illustration purposes only. Please refer to product description.

| | |
|--------------------|---|
| Part number | 09 18 014 7007 |
| Specification | SEK CAB FLAT SH RND AWG28/7 14P 30,48m |
| HARTING eCatalogue | https://b2b.harting.com/09180147007 |

Identification

| | |
|---------------|----------------------|
| Category | System cabling |
| Element | Bulk cables |
| Specification | Not assembled |
| Type of cable | Copper cable (round) |

Version

| | |
|-----------------|----------|
| Cable length | 30.48 m |
| Shielding | Shielded |
| Number of cores | 14 |
| Core structure | AWG 28/7 |

Technical characteristics

| | |
|------------------------------|--|
| Impedance | 100 Ω |
| Limiting temperature | -30 ... +75 °C unmoved -20 ... +75 °C moved |
| Conductor resistance @ 20 °C | $\leq 216 \Omega/\text{km}$ |

Material properties

| | |
|------------------|-----------|
| Material (cable) | PVC |
| Colour (cable) | Grey |
| RoHS | compliant |
| ELV status | compliant |
| China RoHS | e |



Pushing Performance

Material properties

| | |
|-----------------------------|----|
| REACH Annex XVII substances | No |
| REACH ANNEX XIV substances | No |
| REACH SVHC substances | No |

Specifications and approvals

| | |
|----------------|-------------------|
| Specifications | UL 1581 Sec. 1061 |
| | UL PLCC, CL2 |
| CE | Yes |

Commercial data

| | |
|--------------------------------|--|
| Packaging size | 1 |
| Net weight | 0.66 g |
| Country of origin | Germany |
| European customs tariff number | 85444993 |
| eCl@ss | 27061801 Data and communication cable (copper) |