


PX0856/KS Datasheet

Product Name // Rear Panel Mount Connector PX0856
Series Cat 8 Shielded Keystone Toolless IDC

 [View Product Page](#)

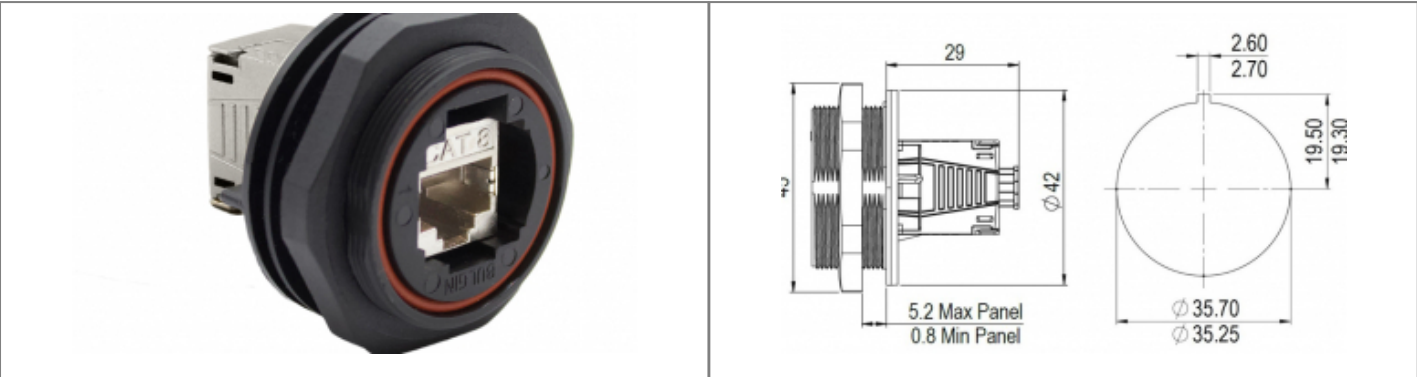

// Product Description:

- ⬢ Rear Panel Mounting Connector
- ⬢ Water and dustproof to IP68 when mated
- ⬢ Single hole fixing
- ⬢ Supplied with panel sealing gasket
- ⬢ Cat 8 shielded IDC Keystone connector
- ⬢ PX0711 Sealing Cap available separately to maintain IP rating of unmated connectors
- ⬢ Mate with Cat 8 PX0857, PX0858 Standard Series Flex Cable Connectors for Cat8 performance
- ⬢ Also mates with all Standard Series Flex Cable Connectors for backwards compatibility

// General Information:

Product Display Title:	Front Panel Mount Connector
Product Family:	Circular Data Connectors
Product Series:	Standard Buccaneer - Ethernet
Body Colour:	Black
Body Material:	Nylon 66
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	1.5A
Data Cable Type:	IP68 RJ45 Coupler
Diameter Over Coupling Ring Mm:	38.1mm
Durability:	1200 cycles
Ethernet Category:	Cat 8
Flamability Rating:	UL94V-0
Function:	Rear Panel Mount Connector
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+60°C
Min Operating Temperature:	-20°C
Max Panel Thickness:	5.2mm
Min Panel Thickness:	0.8mm
Number Of Contacts:	8 Contacts
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	EN60068-2-52 Test Kb Salt Mist (Cyclic) Marine Severity Level 1
Voltage Max:	72V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)