




RELAYS, CONTACTORS & SWITCHES

MID-RANGE

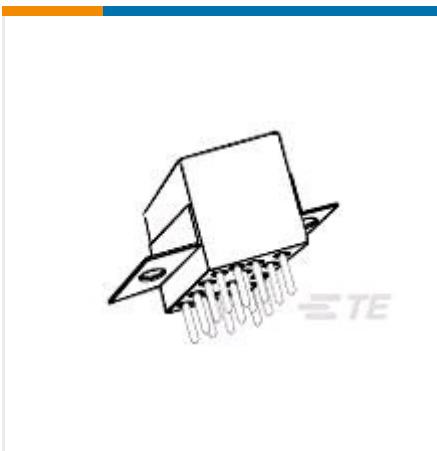

✓ Active

TE CONNECTIVITY (TE)

FCA-410-DY8

CII | FCA 10-25 Amp Relay

FCA-410-DY8

TE Internal Number: 1617756-9

Not EU RoHS Compliant

Not EU ELV Compliant

Contact Arrangement 4 Form C, 4PDT, 4 C/O

Coil Suppression Diode Without

Auxiliary Contacts Without

Terminal Plating Tin-Lead

Contact Current Rating (A) 10

PRODUCT DRAWING
 English

DOCUMENTATION

Product Drawings

FCA-410-DY8

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Terminal Configuration Socket Pins

Relay Type Military/Aerospace Mid-Range

Product Type Relay

Enclosure Type Hermetically Sealed

Electrical Characteristics

Coil Suppression Diode Without

Coil Voltage Rating (VAC) 115

Coil Current (A) .04

Back EMF Suppression Without

Coil Magnetic System Polarized, Monostable

Shock 200G's, 6ms

Actuating System AC

Vibration 30G's, 70 – 3000Hz

Signal Characteristics

Frequency (Hz) 400

Contact Features

Contact Arrangement 4 Form C, 4PDT, 4 C/O

Auxiliary Contacts Without

Terminal Plating Tin-Lead

Contact Current Rating (A) 10

Contact Base Material Silver Cadmium Oxide

Mechanical Attachment

Mounting Type Raised Vertical Flange Mount

Usage Conditions

Operating Temperature Range (°C) -70 – 125

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
