

■Features

- 45 ° focusing angle
-
-
-
-


■Applications

- Non-long-range lighting with medium area
-
-
-

■Specification


Item	Value
Transmittance	93%
Material	PMMA
Standard	SGS/ROHS
Temperature	-35°C-90°C
Surface Treatment	Matt

■Outline Dimension

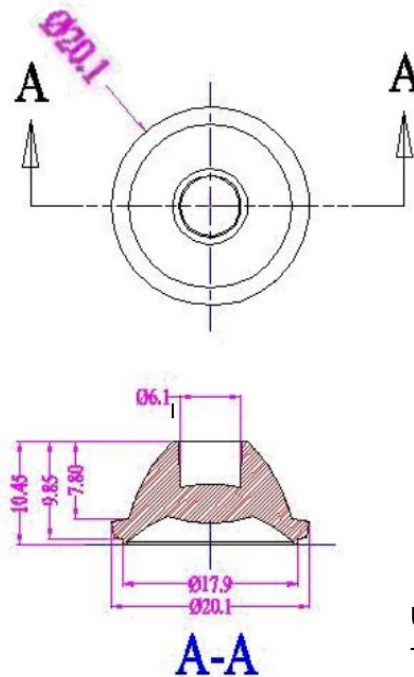

Unit:mm
Tolerance: ± 0.3 mm

■Photos

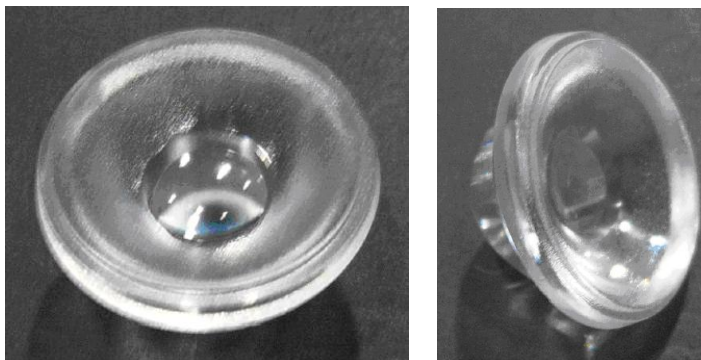

■ Beam Pattern

