




**Part Number :** [395051009](#)

**Product Description :** 3.50mm Pitch Eurostyle  
Vertical PCB Header, with Threaded Retention Inserts,  
9 Circuits

**Series Number :** 39505

**Status :** Active

**Product Category :** Terminal Blocks and Barrier  
Strip

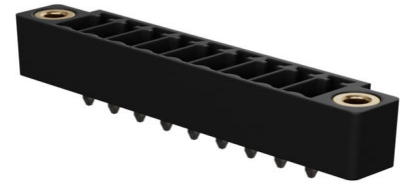

---

## Documents and Resources

### Drawings

[395051009 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

### Specifications

[PS-39500-001-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

### [Compliance Statements](#)

- EU RoHS

- REACH SVHC
- Low-Halogen

#### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

## Part Details

### General

Status	Active
Category	Terminal Blocks and Barrier Strip
Series	39505
Description	3.50mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, 9 Circuits
Application	Wire-to-Board
Component Type	PCB Header
Product Name	Eurostyle Pluggable
Type	PCB Terminal Blocks and Connectors
UPC	822350445481

### Agency

UL	E48521
----	--------

### Electrical

Current - Maximum per Contact	8.0A
Voltage - Maximum	300V

### Physical

Circuits (Loaded)	9
-------------------	---

Circuits (maximum)	9
Color - Resin	Black
Entry Angle	N/A
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Vertical
Panel Mount	No
PCB Thickness - Recommended	2.50mm
PC Tail Length	3.50mm
Pitch - Mating Interface	3.50mm
Pitch - Termination Interface	3.50mm
Polarized to Mating Part	Yes
Shrouded	Shrouded
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size (AWG)	N/A

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
3.50mm Pitch Eurostyle Horizontal Plugs	<u>39504</u>
3.50mm Pitch Eurostyle Vertical Plugs	<u>39507</u>
Mates With	Most 3.50mm Pitch Industry Standard Plugs

---

This document was generated on May 27, 2026