

Menu

NEED HELP?
Contact Customer Service
 (800) 627 - 7100

CONTACT US 

Amphenol®RF

HOME / 031-30232-4

AMPHENOL RF PART NUMBER

031-30232-4

BNC Straight Triax Jack for Size-8 Triax Cable

FIND STOCK & BUY NOW

PRODUCT OVERVIEW



RF Connector, BNC Straight Triax Jack for Size-8 Triax Cable

Product Type Connectors
Product Series Triax
Status Active

ADD TO COMPARE

ADD TO PART LIST

DOWNLOADS

PRODUCT SPECIFICATIONS

Gender	Jack
Orientation	Straight
Termination Style	Cable - Clamp
Impedance (Ohms)	Non-Constant
Body Finish	Nickel
Body Material	Brass
Contact Finish	Gold
Contact Material	Brass
Contact Termination Style	Solder
Insulator Material	PTFE
Cable Group	Special
Cable Type	Size-8 Triax
Coupling Mechanism	Bayonet
Max Frequency (GHz)	0.5
Polarity	Standard
Min. Temp. (Celsius)	-65
Max. Temp. (Celsius)	165
Mating Cycles	500

PRODUCT COMPLIANCE



Product compliance documentation, if available is listed below:

RoHS 2 (EU)	Compliant with Exemption 6C - View Certificate
-------------	--

Additional compliance information is available in our [Product Compliance Center](#).

AMPHENOL RF

COMPANY PROFILE
NEWS AND ARTICLES
LOCATIONS
CAREERS
CAPABILITIES
QUALITY


QUICK LINKS

DISTRIBUTOR INVENTORY
COMPETITOR CROSS REFERENCE
PRODUCT COMPLIANCE
LITERATURE
EXTRANET LOG-IN

CONTACT US

CONTACT FACTORY
LOCAL REPRESENTATIVES
DISTRIBUTOR LISTING

FOLLOW US

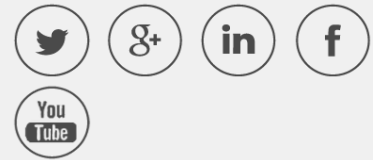

NEWSLETTER

Copyright © 2014 Amphenol RF. All Rights Reserved.

Copyright | [Terms & Conditions](#) | [Privacy Policy](#) | [Logos](#) | [Amphenol.com](#)