


YOUR SELECTED PRODUCT

For other versions than the listed available standard types, please contact PRECI-DIP

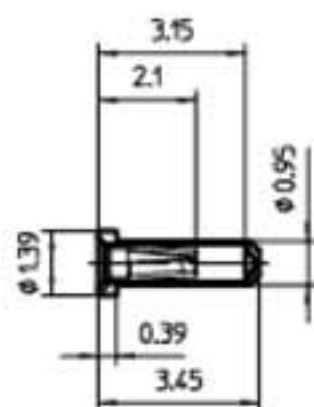

SPECIFICATIONS:

Socket contact without solder tail / SMD socket contact

- Materials: body brass, contact clip BeCu
- Electrical contact resistance max. 20 milliohms
- Mechanical life min. 500 cycles

AVAILABLE STANDARD TYPES

Ordering Part Number		Plating Body	Plating Clip	Insertion	Extraction	Dia.Gauge	Max Current
01412-13-1110	RoHS	0.25µm Au	0.75µm Au	1.00 N	0.40 N	0.43 mm	3.0 A
01412-83-1110	RoHS	5µm Sn	0.75µm Au	1.00 N	0.40 N	0.43 mm	3.0 A
01412-87-1110	RoHS	5µm Sn	Flash Au	1.00 N	0.40 N	0.43 mm	3.0 A
01412-83-2110	RoHS	5µm Sn	0.75µm Au	0.80 N	0.40 N	0.46 mm	3.0 A
01412-87-2110	RoHS	5µm Sn	Flash Au	0.80 N	0.40 N	0.46 mm	3.0 A

<< Back