

# CD 80X60 - Cable duct

3240194

<https://www.phoenixcontact.com/us/products/3240194>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable duct for installation and mounting in control cabinets, gray, comprising upper part and mounting base, width: 80 mm, height: 60 mm, length: 2000 mm

## Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool

## Commercial data

Item number	3240194
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BE74
Product key	BE7431
Catalog page	Page 581 (C-3-2019)
GTIN	4046356459204
Weight per piece (including packing)	1,400 g
Weight per piece (excluding packing)	1,400 g
Customs tariff number	39259020
Country of origin	DE

# CD 80X60 - Cable duct

3240194

<https://www.phoenixcontact.com/us/products/3240194>



## Technical data


### Product properties

Product type	Wiring duct
--------------	-------------

### Connection data

Nominal cross section	2970 mm²
-----------------------	----------

### Dimensions

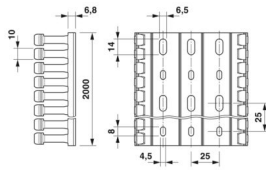Dimensional drawing	
Width	80 mm
Height	2000 mm
Depth	60 mm
Length	2000 mm

### Material specifications

Color	gray
Material	PVC
Flammability rating according to UL 94	V0
Components	Lead-free

### Cable/line

Halogen-free	no
--------------	----

### Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-5 °C ... 60 °C


# CD 80X60 - Cable duct

3240194

<https://www.phoenixcontact.com/us/products/3240194>



## Drawings

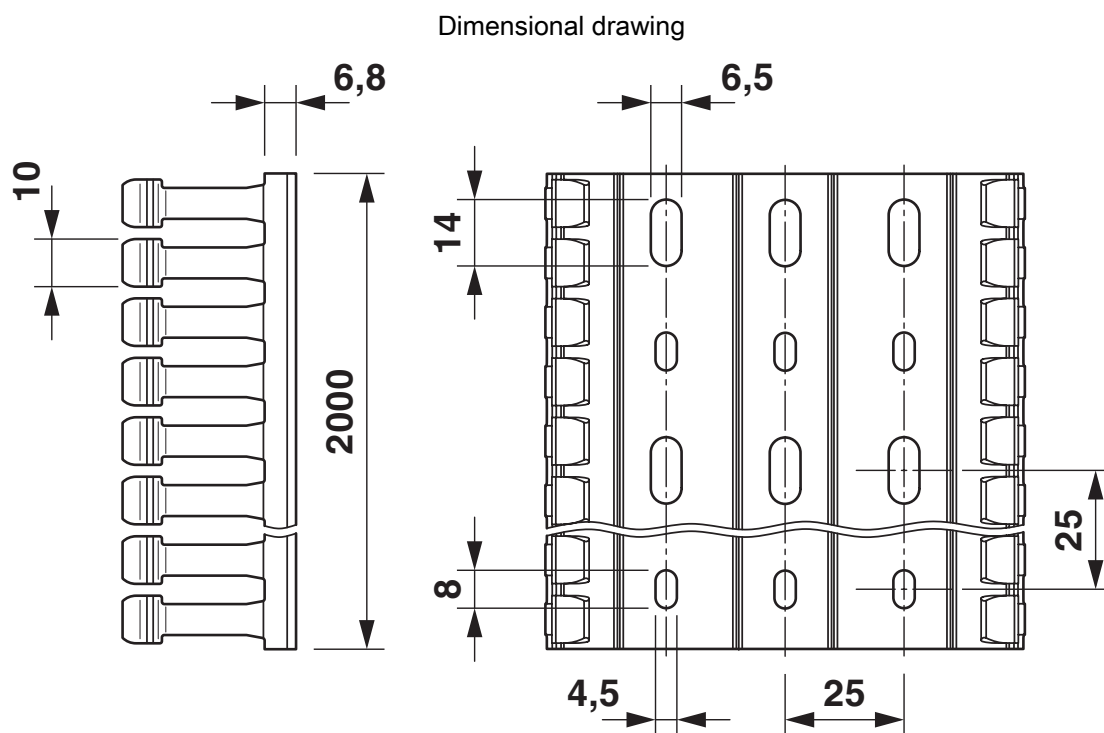

Base perforation according to DIN EN 50085

# CD 80X60 - Cable duct

3240194

<https://www.phoenixcontact.com/us/products/3240194>



## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/3240194>



**VDE Zeichengenehmigung**

Approval ID: 40058456



**cULus Recognized**

Approval ID: E328576



**cCSAus**

Approval ID: 80202282

# CD 80X60 - Cable duct



3240194

<https://www.phoenixcontact.com/us/products/3240194>

## Classifications

### ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

### ETIM

ETIM 9.0	EC000012
----------	----------

### UNSPSC

UNSPSC 21.0	39131700
-------------	----------

# CD 80X60 - Cable duct



3240194

<https://www.phoenixcontact.com/us/products/3240194>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

# CD 80X60 - Cable duct

3240194

<https://www.phoenixcontact.com/us/products/3240194>



## Accessories

### RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/us/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

### RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/us/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

## CD 80X60 - Cable duct

3240194


<https://www.phoenixcontact.com/us/products/3240194>



## CD COVER 80 - Cover profile

3240288

<https://www.phoenixcontact.com/us/products/3240288>

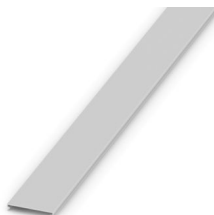

Cover for cable duct, gray, width: 80 mm, length: 2000 mm

---

## UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/us/products/1212478>



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

## CD 80X60 - Cable duct

3240194

<https://www.phoenixcontact.com/us/products/3240194>



## UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/us/products/1212509>



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

---

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)