



BMMN001010301R2MX1

Search by :

- Part Number
- Characteristics
- Cross reference




MP

?

Closed Magnetic Circuit Type
Molding Processing & for Ultra High Current

Series Pdf

Product detail	
L(mm) ±	10±0.3
W(mm) ±	11.5Max.
T(mm) ±	3.0Max.
Inductance(uH)	1.2
Tolerance(±%)	20
Test Frequency	100kHz,0.25V
RDC(Ω)Max	0.0152
RDC(Ω)Typ	0.0125
Isat(A)Typ	24
Isat(A)Max	20
Irms(A)Typ	10.5
Irms(A)Max	9.5
Operating Temperature	−55℃~125℃(Including self - temperature rise)

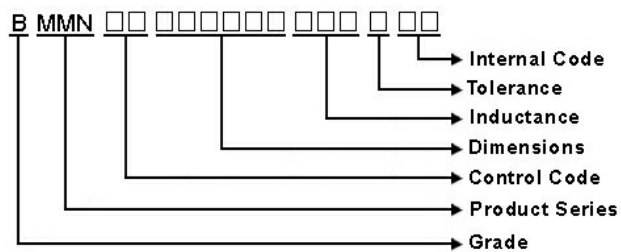

Products

Power Inductor
EMI-Common Mode Choke
EMI-Bead
RF-Signal Inductor
RF-Passives/Antennas
LAN Transformer
Resistor & Current Sensor

Applications

Automotive
Industrial
Server/DataCenter
Communication
Mobile and Tablet
Computer/Laptop
Consumer

Design Tools

Simulation Tool
Product Search Engine
E-Catalogue

About Us

Corporate Overview
Corporate Milestones
Core Technology
Certificates & Awards
Quality and Social Responsibility

Investor

Financial Information
Corporate governance
Downloaded from Arrow.com

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.