



Nylon Cable Clamps, Adjustable

Features

- Black Nylon 6/6 backed with Adhesive Tape
- Easy to Install, Open, and Close for Unlimited Usage
- One Size can Accommodate Various Cables

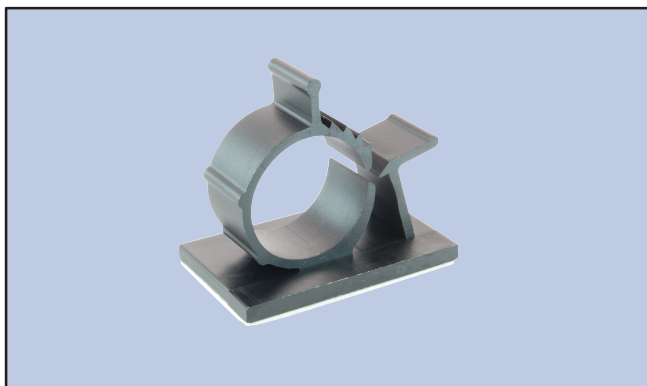

CC-02

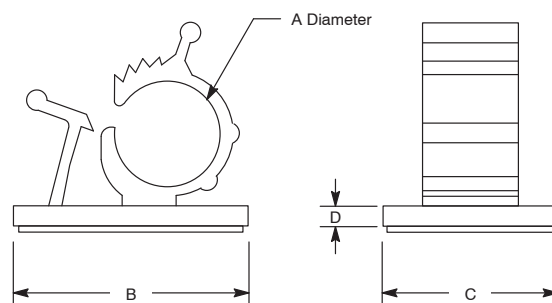


Nylon Cable Clamps, Adjustable

NTE Type No.	Description	Clamping Range, A		B	C	D	Qty. per Bag	Diag No.
		Min	Max					
NEW 04-ACC10	.390" Adjustable	.311 / 7.9	.390 / 9.9	1.000 / 25.4	.750 / 19.05	.078 / 1.98	10	CC-02
NEW 04-ACC20	.485" Adjustable	.390 / 9.9	.485 / 12.32	1.281 / 32.54	.750 / 19.05	.078 / 1.98	10	CC-02
NEW 04-ACC30	.560" Adjustable	.445 / 11.3	.560 / 14.22	1.455 / 36.7	.750 / 19.05	.078 / 1.98	10	CC-02
NEW 04-ACC40	.765" Adjustable	.620 / 15.75	.765 / 19.43	1.660 / 42.16	1.000 / 25.4	.109 / 2.78	10	CC-02
NEW 04-ACC50	.935" Adjustable	.755 / 19.18	.935 / 23.75	1.750 / 44.45	1.000 / 25.4	.109 / 2.78	10	CC-02


Nylon Cable Clamps, Ladder Style, Adjustable

Features

- Nylon 6/6 backed with Adhesive Tape
- Easy to Install, Open, and Close for Unlimited Usage
- One Size can Accommodate Various Cables

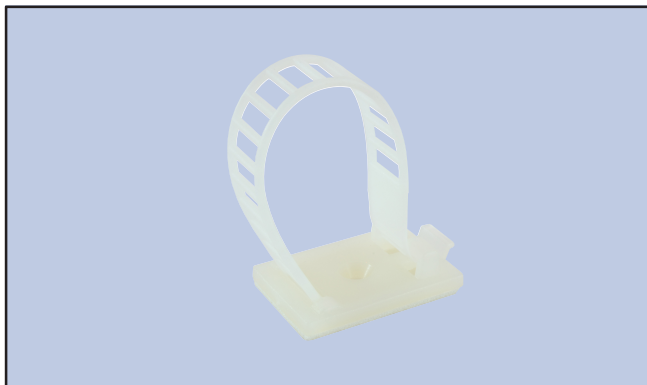

CC-03

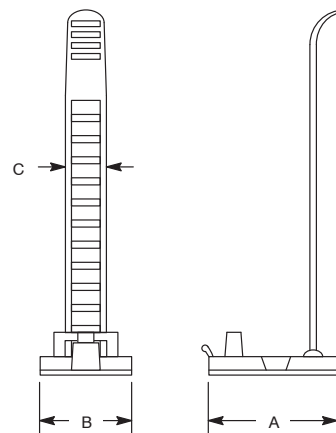

Nylon Cable Clamps, Ladder Style, Adjustable

NTE Type No.	Description	A	B	C	Max Bundle Dia.	Qty. per Bag	Diag No.
NEW 04-LACC19	.669" Adjustable	.984 / 25.0	.709 / 18.0	.311 / 7.9	.669 / 17.0	10	CC-03
NEW 04-LACC29	.866" Adjustable	1.200 / 30.5	.827 / 21.0	.472 / 12.0	.866 / 22.0	10	CC-03
NEW 04-LACC39	1.024" Adjustable	1.200 / 30.5	.827 / 21.0	.472 / 12.0	1.024 / 26.0	10	CC-03