

Female test connector - PSB 3/10/4 - 0601292

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Female test connector, color: silver

Your advantages

- ✓ Test sockets PSB ... are used for a reliable test connection
- ✓ With PSB 6/5/6, the test plug with a 4 mm diameter is used
- ✓ All test sockets are screwed into the bridge shaft

RoHS

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
GTIN	 4 017918 003012
GTIN	4017918003012
Weight per Piece (excluding packing)	0.940 g
Custom tariff number	85366990
Country of origin	Poland

Technical data

General

Color	silver
-------	--------

Dimensions

Length	10 mm
Width	4 mm
Pin diameter	2.4 mm

Female test connector - PSB 3/10/4 - 0601292

Technical data

Dimensions

Screw thread	M3
Tightening torque, min	0.5 Nm
Tightening torque max	0.6 Nm

Ambient conditions


Operating temperature	-40 °C ... 80 °C
-----------------------	------------------

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Dimensional drawing

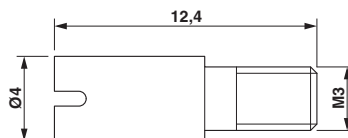

Classifications

eCl@ss

eCl@ss 10.0.1	27440313
eCl@ss 11.0	27440313
eCl@ss 4.0	27141100
eCl@ss 4.1	27141100
eCl@ss 5.0	27141100
eCl@ss 5.1	27141100
eCl@ss 6.0	27141100
eCl@ss 7.0	27440313
eCl@ss 9.0	27440313

ETIM

ETIM 2.0	EC000897
ETIM 3.0	EC000897
ETIM 4.0	EC002255
ETIM 6.0	EC002255

Female test connector - PSB 3/10/4 - 0601292

Classifications

ETIM

ETIM 7.0	EC002255
----------	----------

UNSPSC

UNSPSC 6.01	30211812
UNSPSC 7.0901	39121410
UNSPSC 11	39121411
UNSPSC 12.01	39121411
UNSPSC 13.2	39121410
UNSPSC 18.0	39121410
UNSPSC 19.0	39121410
UNSPSC 20.0	39121410
UNSPSC 21.0	39121410