



TOP VIEW

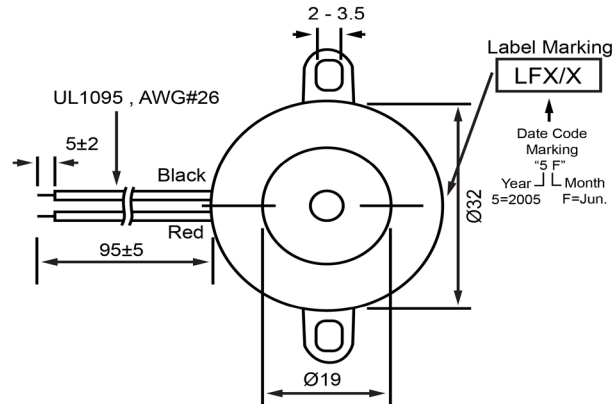

SIDE VIEW

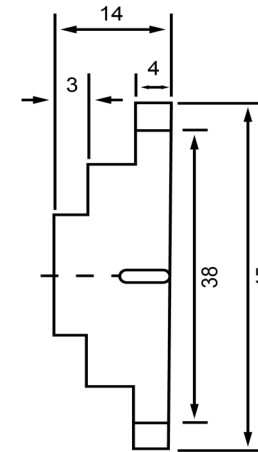

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description		Date	Approved	
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S	
Resonant Frequency	3,900	(Hz)							
Rated Voltage	12	(V)							
SPL @ 10cm	97	(dBA)							
Tone	Single								
Mount Type	Flange								
Voltage Range	3 ~ 28	(V)							
Max Rated Current	15	(mA)							
Housing Material	ABS								
Operating Temperature	-20 ~ +60	°C							
Storage Temperature	-20 ~ +60	°C		Drawn by	Date	Checked by	Date	Approved by	Date
Weight	8	(g)		A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			DB UNLIMITED	Piezo Indicator			IP323912-1		