


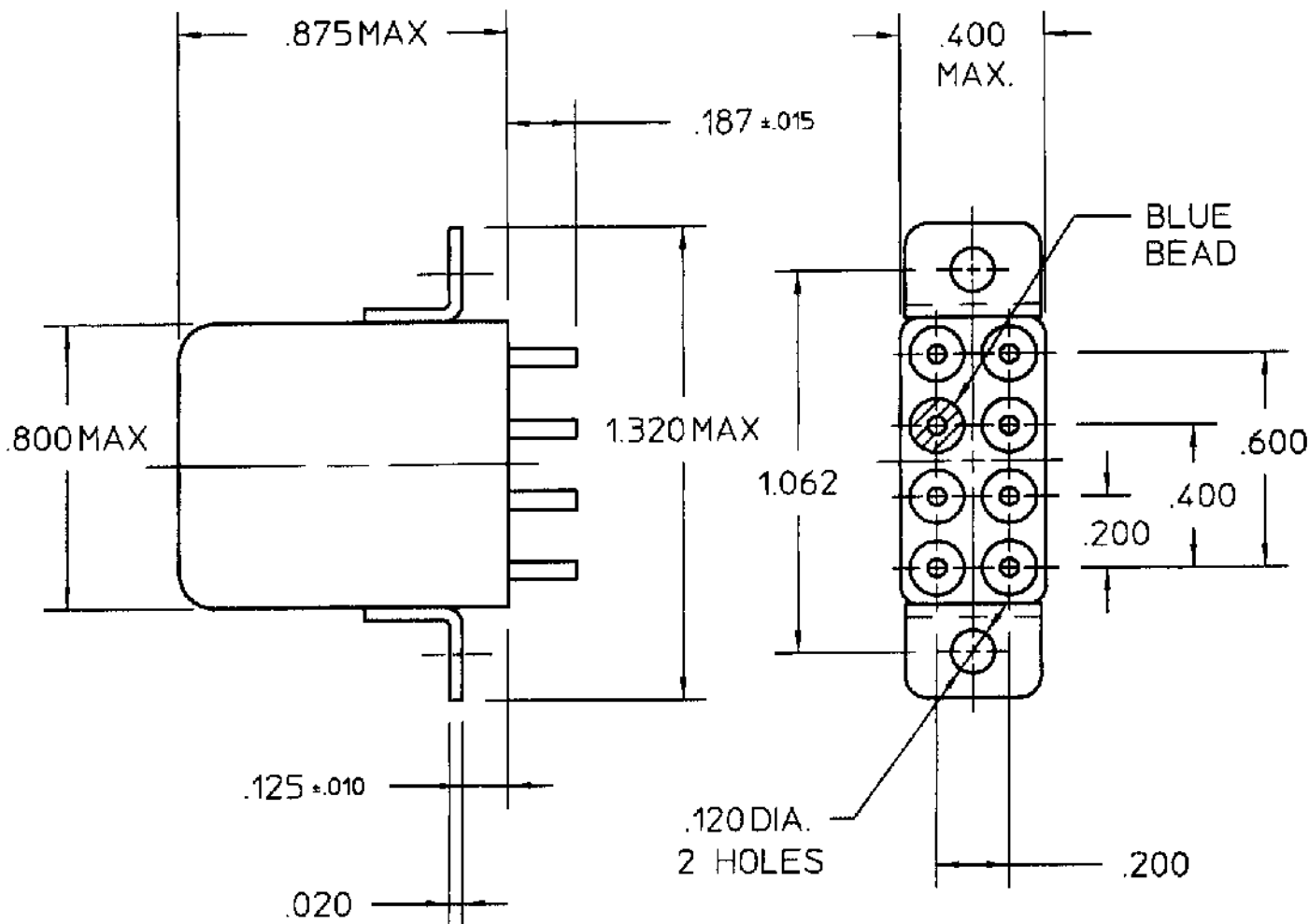

REV. 0

DCO 16651


COIL: @ 25°C
 RESISTANCE 9,100 OHMS ± 10%
 NOMINAL VOLTAGE 110.0 VDC
 MUST OPERATE 51.0 VDC
 MUST RELEASE 5.56 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 ± 1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

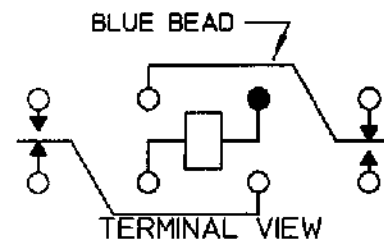

CONTACT RATING: 3 AMPS 28 VDC
 RESISTIVE 100,000 OPERATIONS

DR. PBB 11/30/00

CK. TLG 11-30-00

CII Technologies
 advanced control electronic solutions

CUST. C. I. I. STD.

CUST. NO. REV.

"FW" RELAY

FW1220R00