




DB UNLIMITED

Part Number:	1	
	DRAWN	9/24/2015
	CJ	
Description:	CHECKED	9/24/2015
	P.D	
	APPROVED	9/24/2015
J.S		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


SP500104-1

Dynamic Speaker

Top View

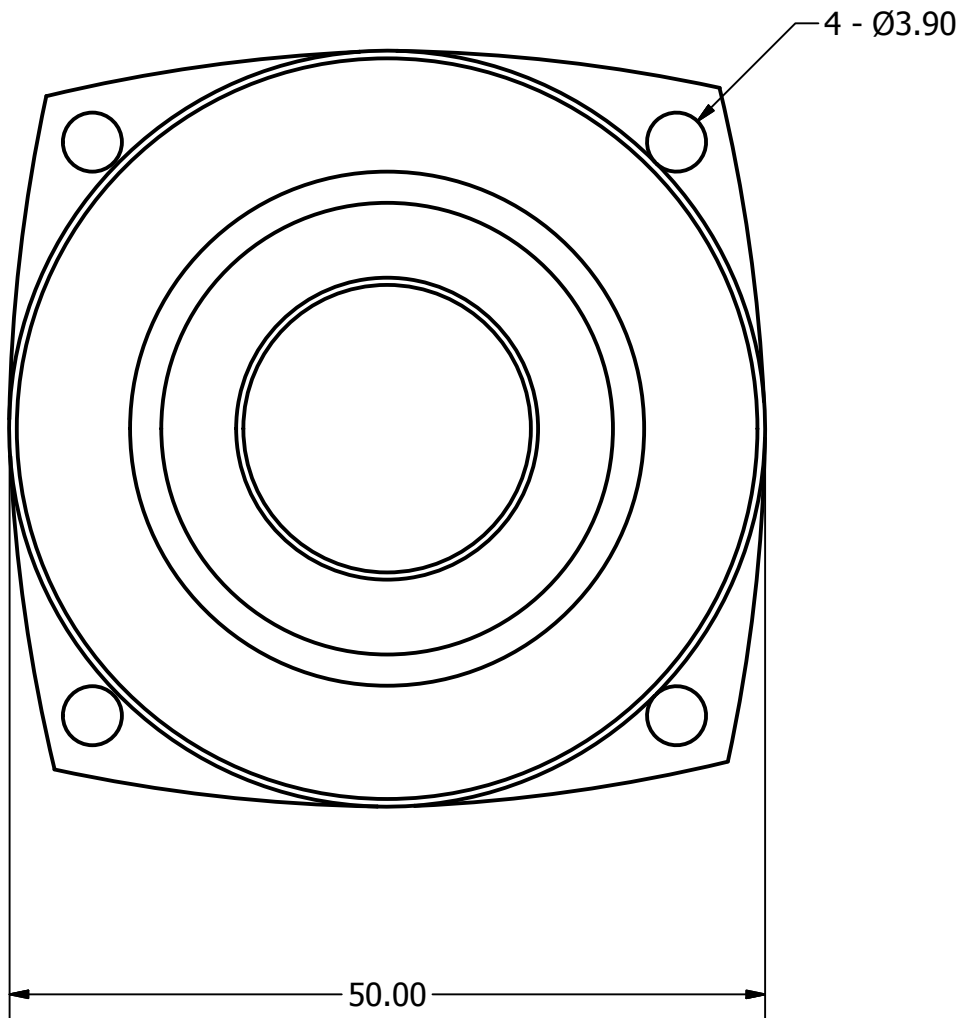

Side View

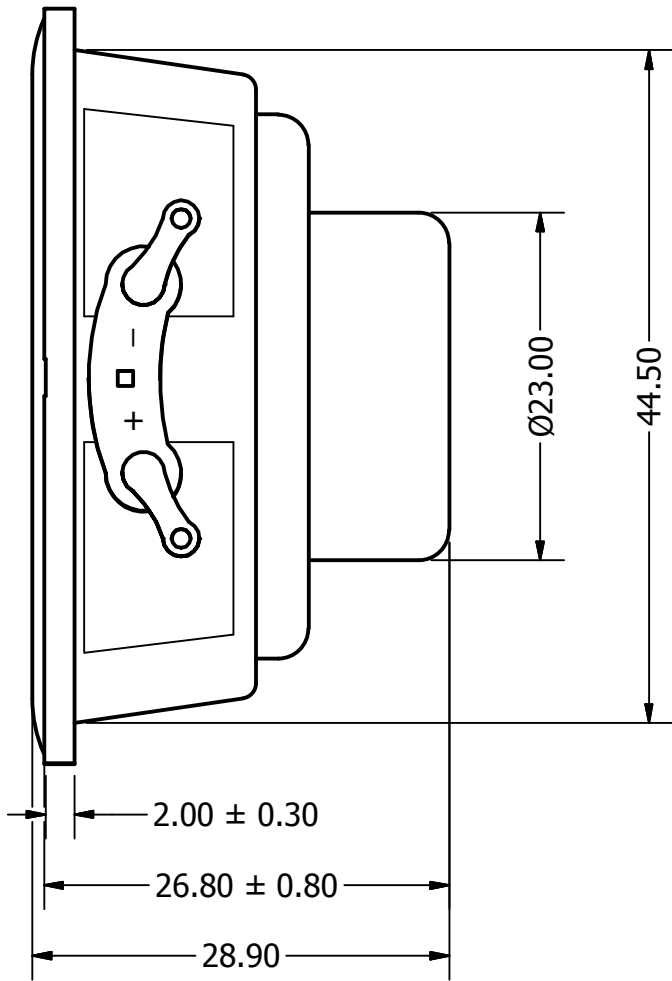

Items	Specifications	Conditions
Sound Pressure Level	101	dB (@ 10cm)
Resonant Frequency	135	Hz
Frequency Range	135 ~ 20,000	Hz
Nominal Power	5	W
Max. Power	10	W
Impedance	4	Ω
Cone Material	Paper	
Mount Type	Frame	
Storage Temperature	-25 ~ +55	°C
Operating Temperature	-25 ~ +55	°C
Weight	30	g

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	9/24/2015	J.S.
NOTES			
1) All dimensions are in mm unless otherwise noted			
2) All tolerances are ± 0.5 mm unless otherwise noted			
3) All parts meet RoHS			
4) Subject to change or redrawn without notice			