



ZTTS Series

Ceramic Resonator with built-in capacitors

STANDARD SPECIFICATIONS



Part Number	Frequency Range MHz.	Frequency Accuracy @ 25°C	Temperature Stability °C	Aging For 10 Years	Operating Temperature °C	C1	C2
ZTTS-MG	2.00 ~ 6.99	± 0.5%	± 0.3%	± 0.3%	-20 ~ +80	30 pF	30 pF
ZTTS-MT	7.00 ~ 13.00	± 0.5%	± 0.4%	± 0.4%	-20 ~ +80	30 pF	30 pF
ZTTS-MX	13.01 ~ 20.00	± 0.5%	± 0.3%	± 0.3%	-20 ~ +80	30 pF	30 pF
ZTTS-MX	20.01 ~ 25.99	± 0.5%	± 0.3%	± 0.3%	-20 ~ +80	15 pF	15 pF
ZTTS-MX	26.00 ~ 35.00	± 0.5%	± 0.3%	± 0.3%	-20 ~ +80	5 pF	5 pF

Part Number Guide

Sample Part #: **ZTTS -MG - 2.00 -T**

ZTTS – Package – Frequency – Packaging

Packaging: - = Bulk , -T = Tape and Reel

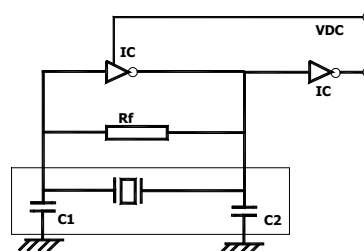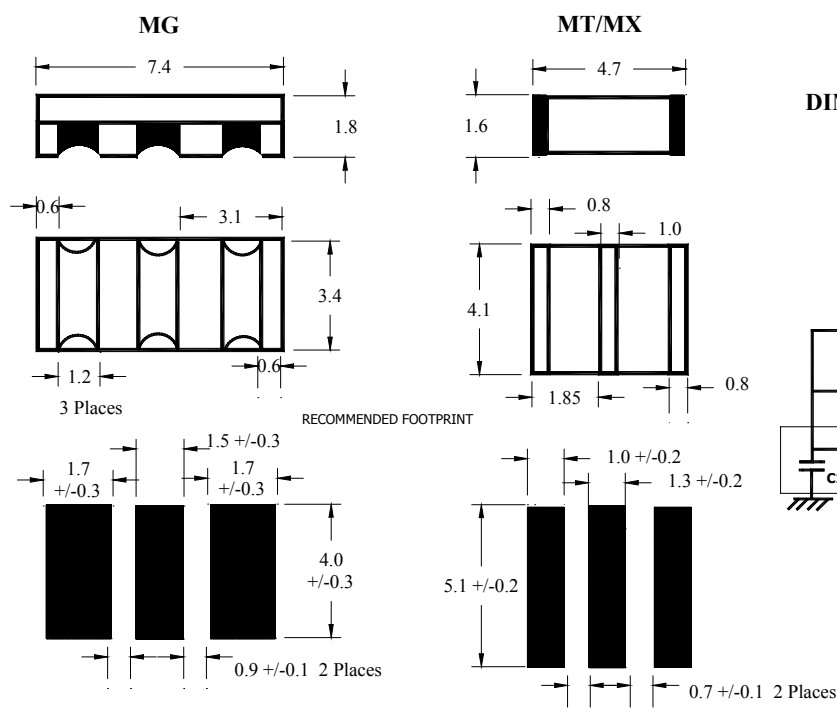

MG / MT IC: C D 4069 UBPX2
MX IC: T C 74HCU04