


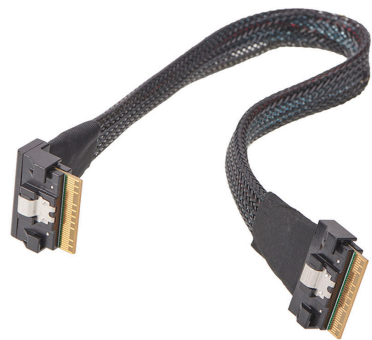

Part Number : [2073701000](#)
Product Description : SlimSAS Cable Assemblies, SAS 4.0, Straight Plug-to-Right-Angle Plug, 4x (38 Circuits), 32 AWG, 0.152m Length
Series Number : 207370
Status : Active
Product Category : Power and Signal Cable Assemblies




Documents & Resources

Drawings
[2073701000_sd.pdf](#)

Specifications
[2073680002-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

Part Details

General

Status	Active
Category	Power and Signal Cable Assemblies
Series	207370
Description	SlimSAS Cable Assemblies, SAS 4.0, Straight Plug-to-Right-Angle Plug, 4x (38 Circuits), 32 AWG, 0.152m Length
Assembly Configuration	Dual Ended Connectors
Connector to Connector	SlimSAS-to-SlimSAS
Product Name	SlimSAS
UPC	191130022649

Electrical

Current - Maximum per Contact	0.5A
Impedance	100Ω
Voltage - Maximum	30V AC

Physical

Cable Length	0.152m
Circuits (Loaded)	38
Circuits (maximum)	38
Color - Resin	Black
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Resin	Polycarbonate
Net Weight	12.000/g
Number of Rows	2
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	Ribbon Cable
Wire Size (AWG)	32

This document was generated on Apr 19, 2025