

AFSI001211098R2M05

Search by :

Part Number

Characteristics

Cross reference




NEW ?

Closed Magnetic Circuit Type

Series Pdf

Product detail	
L(mm) ±	12.0±0.5
W(mm) ±	11.0±0.5
T(mm) ±	8.8Max.
Inductance(uH)	8.2
Tolerance(±%)	20
Test Frequency	100kHz,1V
RDC(Ω)Max	0.009
RDC(Ω)Typ	0.0082
Isat(A)Typ	18
Irms(A)Typ	16
Operating Temperature	−55℃~155℃ (Including self - temperature rise)

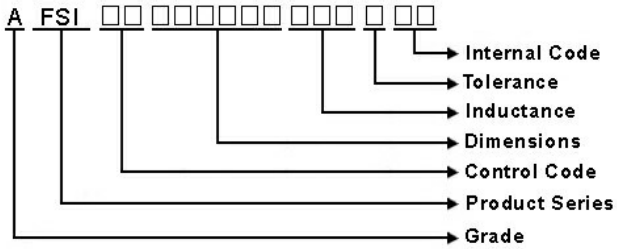

Products

Power Inductor
EMI-Common Mode Choke
EMI-Bead
RF-Signal Inductor
RF-Passives/Antennas
LAN Transformer
Resistor & Current Sensor

Applications

Automotive
Industrial
Server/DataCenter
Communication
Mobile and Tablet
Computer/Laptop
Consumer

Design Tools

Simulation Tool
Product Search Engine
E-Catalogue

About Us

Corporate Overview
Corporate Milestones
Core Technology
Certificates & Awards
Quality and Social Responsibility

Investor

Financial Information
Corporate governance
Stakeholder Contacts

[Media Center](#)
[New Products](#)
[Events](#)
[Product Notices](#)

Contact Us

[Contact Info](#)
[Contact Form](#)
[Join Chilisín](#)

[Terms of Use](#)
[Privacy policy](#)
[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.