

**Key Features:**

- Ergonomically designed for hand-held comfort.
- Choice of five sizes and six color combinations:
 - » Light gray case w/ gray overmold
 - » Black case w/ gray overmold
 - » Black case w/ black overmold
 - » Translucent blue case w/ black overmold
 - » Red case w/ black overmold
 - » Yellow case w/ black overmold
- Some sizes offered with battery doors and hardware (see table for more information).
- Molded in general purpose ABS plastic with an overmold, soft plastic grip.
- Top cover is recessed for membrane display or keypad.
- P.C. board standoffs are molded into case (drawings on our [web site](#) for details).
- Most models include a removable end panel for easy modifications.
- Battery door & compartment version includes 4 battery clips (for 2 - AA batteries) and a 9 volt (PP3) battery clip.



For a similar water-tight enclosure, try "1553W" on page 41

Accessories**Belt Clip Kits**

1599CLIP (black)
1599CLIPGY (gray)

**PC Board Kits
for "B", "C" and "D" Sizes**

1553BPCB
for "B" and "C"

1553DBPCB
for "D"

**IR Panels for "B"
and "D" Sizes**

1553BIR-BULK



1553DIR-BULK



www.hammondmfg.com

USA

(716) 630-7030

Canada

(519) 822-2960

Quebec

(450) 975-1884

Europe (UK)

01256 812812

Australia

+61-8-8240-2244





Battery Door Version
Shown with closed
door, 9V battery clip,
and AA battery clips.



Battery door version shown above as a complete kit. Each enclosure includes multiple battery options.

1553 enclosures are available with or without battery compartments.

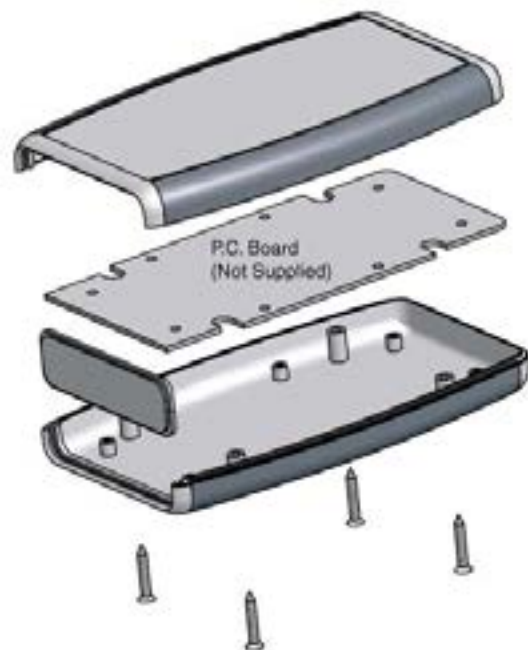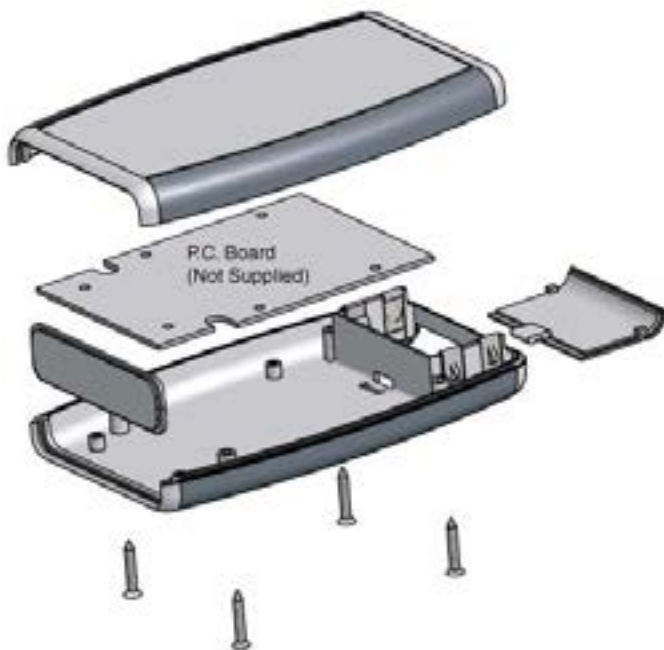



Critical Data, No Questions

PDF Data Sheets, 2D AutoCAD, and 3D Models are available for download immediately from our web site.



Part Number	Enclosure Color	Soft Side Color	Battery Door	Units	Length	Width	Depth
1553AABK	Black	Gray	No	inches mm	2.95 75	1.97 50	0.67 17
1553AAGY	Grey	Gray	No				
1553ABK	Black	Gray	No	inches mm	3.94 100	2.41 61	0.67 17
1553AGY	Grey	Gray	No				
1553BBK	Black	Gray	No	inches mm	4.62 117	3.11 79	0.95 24
1553BBKBAT	Black	Gray	Yes				
1553BBK BK	Black	Black	No				
1553BBK KBAT	Black	Black	Yes				
1553BGY	Grey	Gray	No				
1553BGYBAT	Grey	Gray	Yes				
1553BRDBK	Red	Black	No				
1553BRDBKBAT	Red	Black	Yes				
1553BTBUBK	TransBlue	Black	No				
1553BTBUBKBAT	TransBlue	Black	Yes				
1553BYLBK	Yellow	Black	No	inches mm	4.62 117	3.11 79	1.3 33
1553BYLBKBAT	Yellow	Black	Yes				
1553CBK	Black	Gray	No				
1553CBKBAT	Black	Gray	Yes	inches mm	4.62 117	3.11 79	0.98 24
1553CGY	Grey	Gray	No				
1553CGYBAT	Grey	Gray	Yes				
1553DBK	Black	Gray	No	inches mm	5.8 147	3.5 89	0.98 24
1553DBKBAT	Black	Gray	Yes				
1553DBK BK	Black	Black	No				
1553DBK KBAT	Black	Black	Yes				
1553DGY	Grey	Gray	No				
1553DGYBAT	Grey	Gray	Yes				
1553DRDBK	Red	Black	No				
1553DRDBKBAT	Red	Black	Yes				
1553DTBUBK	TransBlue	Black	No				
1553DTBUBKBAT	TransBlue	Black	Yes				
1553DYL BK	Yellow	Black	No				
1553DYL KBAT	Yellow	Black	Yes				

