

BPSF00101045102M00

Search by :

Part Number

Characteristics

Cross reference



MP



Closed Magnetic Circuit Type

Series Pdf

Product detail		
L (mm) ±		10.1±0.3
W(mm) ±		10.1±0.3
T (mm) ±		4.5±0.3
Inductance(uH)		1000
Tolerance(±%)		20
Test Frequency		0.5V 1kHz
RDC(ohm)		2.8
RDC Tolerance(±%)		20
Isat(A)		0.32
Irms(A)		0.29


Part Numbering

Dimensions

Packing

Recommended Pattern

Electrical Characteristics

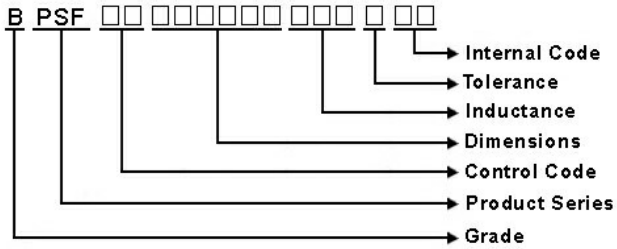

Products

- Power Inductor
- EMI-Noise Suppression
- RF-Signal Inductor
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

- Media Center
- New Products

Contact Us

Contact Info

Contact Form

Join Chilisin

Terms of Use

Privacy policy

Sitemap



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.