

HDC 06B TSS 1M25 WMP**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Our flange-mounted housings made of plastic have a built-in cable gland and a screw interlock. They seal directly onto the panel wall and can therefore be used without an attachment housing. The housings are impressive with their low weight and optimal protection against contamination, water and vibrations.

General ordering data

Version	HDC enclosures, Size: 3, Protection degree: IP66, IP67, in plugged condition, Cable entry from side, Screw, , Size of cable entries: M 25
Order No.	2716750000
Type	HDC 06B TSS 1M25 WMP
GTIN (EAN)	4050118803624
Qty.	1 ST

HDC 06B TSS 1M25 WMP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E223801

Dimensions and weights

Height	96 mm	Height (inches)	3.7795 inch
Net weight	123 g		

Temperatures

Ambient temperature -40 °C... 100 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Cable Gland WMP

Cable diameter, min.	9 mm	Cable diameter, max.	17 mm
AF size	26 mm	Size of cable entries	M 25

Dimensions

Cable entry	w. cable glands	Height of housing B	96 mm
-------------	-----------------	---------------------	-------

General data

Tightening torque	3 Nm	UL 94 flammability rating	V-0
Housing main material	PA	Protection degree	IP66, IP67, in plugged condition
EMC housings	No	Material of locking element	Stainless steel, rust-proof

Version

Number of cable glands	1	Size of cable entries	M 25
Top part/bottom part/lid	upper part	Tightening torque	3 Nm
Number of cable entry sideways	1	Design of housing	Cable entry from side
Design of locking system	Screw	Size	3
Cable entry	w. cable glands	Sealing	NBR
Colour (RAL)	RAL 9011	BG	3
Suitable for ModuPlug®	Yes		

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 9.0	27-44-02-02
ECLASS 9.1	27-44-02-02	ECLASS 10.0	27-44-02-02
ECLASS 11.0	27-44-02-02	ECLASS 12.0	27-44-02-02
ECLASS 13.0	27-44-02-02	ECLASS 14.0	27-44-02-02

Creation date 04.07.2025 02:12:14 MEZ

Catalogue status / Drawings

HDC 06B TSS 1M25 WMP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

ECLASS 15.0



27-44-02-02

HDC 06B TSS 1M25 WMP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

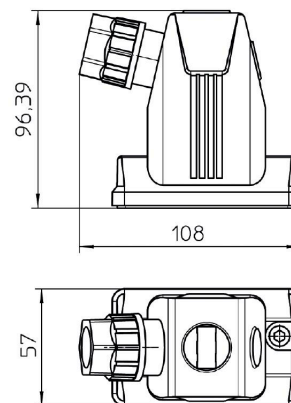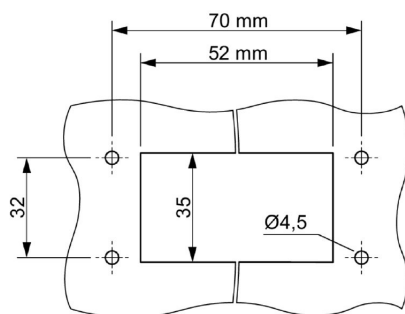

HDC 06B TSS 1M25 WMP**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Mounting brackets**

Our flange-mounted housings made of plastic have a built-in cable gland and a screw interlock. They seal directly onto the panel wall and can therefore be used without an attachment housing. The housings are impressive with their low weight and optimal protection against contamination, water and vibrations.

General ordering data

Type	HDC AF SET WM	Version
Order No.	2716800000	HDC enclosures, Size: , Protection degree:
GTIN (EAN)	4050118803679	
Qty.	1 ST	
Type	HDC AF WM	Version
Order No.	2716790000	HDC enclosures, Size: , Protection degree:
GTIN (EAN)	4050118803662	
Qty.	20 ST	