

RC-0000000E000 - Housing for circular connector



1592813

<https://www.phoenixcontact.com/us/products/1592813>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Housing for circular connector, series: RC, straight, Screw locking mechanism, M23, Radial O-ring, shielded: yes, panel thickness min.: 3 mm, panel thickness max.: 10.5 mm, this item is undergoing a smooth changeover, lead-free alternative in accordance with RoHS II without exception 6c (Pb < 0.1%) possible on request in advance

Commercial data

Item number	1592813
Packing unit	40 pc
Minimum order quantity	1 pc
Sales key	AB31
Product key	ABRAFS
GTIN	4046356192897
Weight per piece (including packing)	37.42 g
Weight per piece (excluding packing)	35.43 g
Customs tariff number	85366990
Country of origin	DE

RC-0000000E000 - Housing for circular connector



1592813


<https://www.phoenixcontact.com/us/products/1592813>

Technical data

Product properties

Product type	Circular connector housing
Series	RC
Application	Signal
Type	Flange housing
Shielded	yes
Thread type	M23

Dimensions

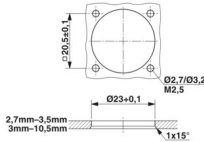Dimensional drawing	
Panel thickness	3 mm ... 10.5 mm

Material specifications

Housing material	Metal
Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Gasket and O-ring material	FPM

Connector

Type	straight
------	----------

Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP67
Ambient temperature (operation)	-20 °C ... 125 °C
Altitude	2000 m

Mounting

Mounting type	Rear mounting/square flange M3 4x M3
Assembly note	4x M3


RC-0000000E000 - Housing for circular connector



1592813

<https://www.phoenixcontact.com/us/products/1592813>

Drawings

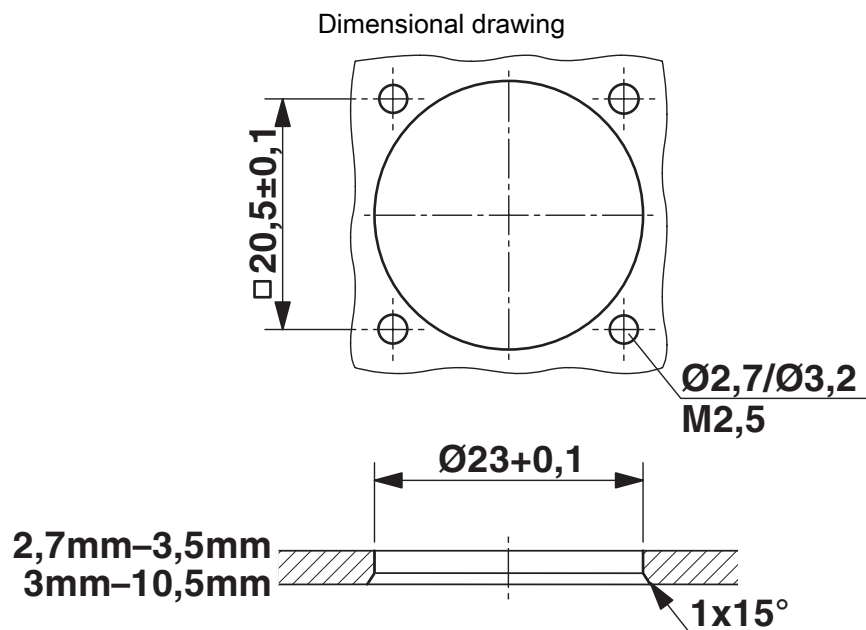

Installation dimensions

RC-0000000E000 - Housing for circular connector



1592813

<https://www.phoenixcontact.com/us/products/1592813>

Classifications

ECLASS

ECLASS-13.0	27440224
-------------	----------

ETIM

ETIM 9.0	EC003556
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

RC-0000000E000 - Housing for circular connector



1592813

<https://www.phoenixcontact.com/us/products/1592813>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	8e2177c0-a688-477e-8d66-69513083fa26

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com