


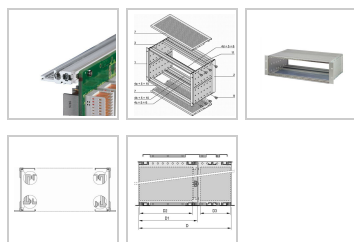

# EuropacPRO kit, flexible design, shielded, for backplane mounting, CompactPCI compatible

**Catalog Number: 24563-457**[Back To Product](#)**Other Views**

- Rear horizontal rail for backplane mounting with insulation strip
- Aluminum construction
- Subrack with side panel type F ("flexible") for CompactPCI plug-in units with high insertion and withdrawal forces
- Internal and external dimensions in accordance with: IEC 60297-3-100, -101, -102, -103, -104, IEEE 1101.1, IEEE 1101.10/11
- Modifications such as cutouts, different finishes or dimensions available
- EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels. Testing in accordance with VG 95373 part 15
- Supplied as space-saving flat-pack
- IP 20, in accordance with IEC 60529
- Horizontal rail type "heavy"

**Note:**

Individual configuration: large variety of variants in height, width and depth; various guide rails for a wide variety of applications; Interior options; accessories and mounting material

**Load:**

Up to 11 kg

**Shock/vibration:**

Up to 2 g

**Design:**

EuropacPRO, Flexible

**EMC Shielding:**

Shielded

**Type:**

Subrack Kit

**Description:**

shielded (IEEE)



**Select product specifications before modifying or adding to project list or requesting a quote.**

Height-U-defining

6 ▾

Rear-I-O-defining

For rear I/O ▾

Depth-mm-defining

275 ▾

[Clear Selection](#)Quantity [Add Item to Project List](#) +**Documents**

- Main Catalog - EuropacPRO
- User Manual
- User Manual
- EMC test report (textile gasket)

**Links**

- Test report
- Native CAD files

 
**Technical Data**

|             |              |
|-------------|--------------|
| Depth mm    | 275.0        |
| Depth D mm  | 275.0        |
| Depth D1 mm | 175          |
| Description | Robust       |
| Other       | For rear I/O |
| Height U    | 6            |
| Width HP    | 84           |

Delivery Comprises:

| Item | Quantity | Description                                                              |
|------|----------|--------------------------------------------------------------------------|
| 1    | 2        | 19" support bracket for EMC textile gasket                               |
| 2    | 2        | Corner profile to rear for EMC textile gasket                            |
| 3    | 2        | Side panel type F                                                        |
| 4 d  | 1        | Centre horizontal rail (ST)                                              |
| 4 c  | 2        | Rear horizontal rail (H-ST) with insulation strip for backplane mounting |
| 4    |          | Front horizontal rail (H-KD)                                             |
| 4 b  | 2        | Rear horizontal rail (L-KD)                                              |
| 4 a  | 2        | Front horizontal rail IEEE (H-LD)                                        |
| 5    | 8        | Threaded insert (pre-fitted)                                             |
| 6    | 4        | Insulation strip, fixed                                                  |
| 7    | 2        | EMC cover plate                                                          |
| 8    | 1        | EMC gasketing material (pre-fitted)                                      |
| 9    | 1        | Assembly kit                                                             |
| 10   | 2        | Perforated strip (pre-mounted)                                           |
| 11   | 2        | Horizontal rail type AB                                                  |
| 12   | 1        | User manual                                                              |


## Accessories



Perforated rail for connector according to EN 60603-2 (DIN 41612), 84 HP, with thread M2.5, PU 4 pieces

20822-048

**Add Item to Project List +**

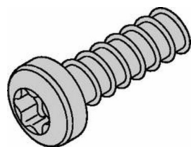

Panhead screw, Torx (2.5x9.3), self-tapping,  
steel zinc plated, PU 100 pcs

24560-141

[Add Item to Project List](#) +



Guide rail with coding, red, 70 mm deep, PU 10 pieces

24560-355

[Add Item to Project List](#) +



Guide rail with coding, grey, 160 mm deep,  
PBT, UL 94 V-0, groove width 2 mm, PU 10  
pieces

24560-  
358

[Add Item to Project List](#) +



Guide rail with coding, red, 160 mm deep, PBT,  
UL 94 V-0, groove width 2 mm, PU 10 pieces

24560-356

[Add Item to Project List](#) +



Guide rail with coding, grey, 70 mm deep, PU  
10 pieces

24560-360


[Add Item to Project List](#) +



Guide rail with coding, green, offset, 160 mm  
deep, PBT, UL 94 V-0, groove width 2 mm, PU  
10 pieces

24560-359

**Add Item to Project List +**

 

19" fixing material kit (screw, washer, nut), (8 × screws, 8 × plastic washers, 8 × cage nuts)

21100-435

Add Item to Project List +

EXPLORE

- About Us
- Services & Capabilities
- News & Events
- Newsletter Subscriptions
- Strategic Partnerships
- Investor Relations

CONTACT

- Customer Service
- Find a Sales Office or Distributor
- Global Locations
- Product Compliance & Certifications
- Partner Login

DOWNLOAD

- Download Center
- Reference Projects
- Videos
- Product Configurators
- Warranties and Terms of Sale & Procurement

© 2018 nVent. All rights reserved | Privacy Policy | Terms of Use | Cookie Policy | Imprint | Site Map

Connect With Us

