
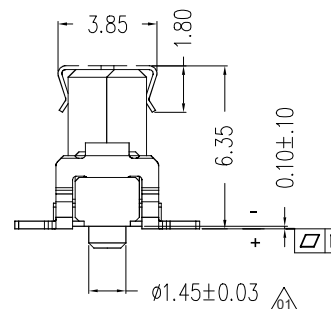


PANCON
CONNECTORS

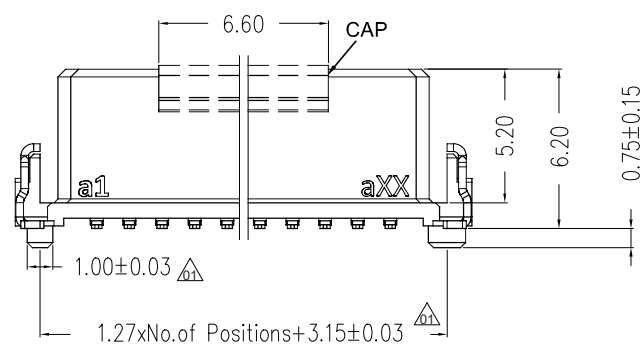

NOTES:
Rated Current:1.2A at 20°C max. 
Contact Resistance:25mΩ Max. 
Withstand Voltage:500V
Insulation Resistance:10000MΩ Min.
Operation Temperature:−55°C to +125°C

Pancon P/N	Pin
033L012-467U	12
033L016-467U	16
033L020-467U	20
033L026-467U	26
033L032-467U	32
033L040-467U	40
033L050-467U	50
033L068-467U	68
033L080-467U	80

02	02.08.2018	modified	vav
01	11.07.2018	modified	vav
00	19.01.2018	issued	vav
REV	DATE	NOTE	NAME

Downloaded from Arrow.com.