


Search within category

GO

BUY NOW

DESIGN / INSTALL

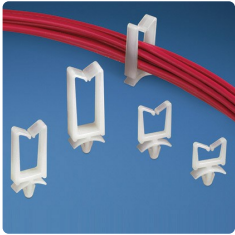

VWS3750-M

Vertical wire saddle, .37" x .50" (9.398mm x 12.7mm) bundle, natural, bulk package.

- Specs
- Packaging Details
- Documents

★ Add to Favorites

Add to BOM

Color	Natural
Environment	Indoor
Flammability Rating	UL94V-2
Height (In.)	0.90
Height (mm)	22.9
Material	Nylon 6.6
Max. Bundle Capacity (In.)	0.37 X 0.50
Max. Bundle Capacity (mm)	9.3 X 12.7
Max. Panel Thickness (In.)	0.04
Max. Panel Thickness (mm)	1.0
Mounting Method	Push Barb
Panel Hole Diameter (In.)	0.19
Panel Hole Diameter (mm)	4.7
UL Recognized	E136577
Width (In.)	0.56
Width (mm)	14.2
RoHS Compliancy Status	Compliant
Min. Order Qty.	1,000