



Active cooling module

DC axial fan + heat sink

XICATO




Highlights:

- Active cooling solution for Xicato light engines
- Xicato XLM light engines
- Industry leading lifetime
- Silent fan operation 7dBA
- Increased lumen output capability
- Commonly used in architectural, pendant, track, spot and downlight applications
- Highly efficient .18 Watt
- Thermal power dissipation up to 53 Watts

Nominal Data		Nominal voltage	Acoustic noise	Thermal power dissipation capability*	Fan speed	Total mass	Power input	Lifetime (at 20°C)	Lifetime (at 20°C)	Lifetime (at 40°C)	Lifetime (at 40°C)
Type	VDC	dB(A)	Watts	RPM	G	Watts	hours	years	hours	years	
PG1W-12-60-L3BN	12	7	53	1800	277	0.18	197,500	22.5	87,500	10	
Note: Voltages are based on the 612F base fan model. Other voltages available upon request. Life expectancy L ₁₀ per IPC 9591. *Application dependant.											

Technical Drawing

Dimensions shown in inches

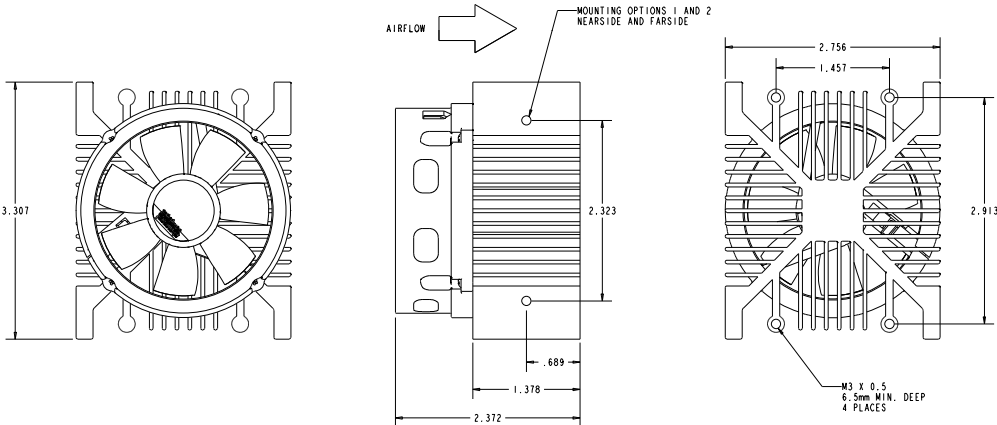

MOUNTING OPTIONS TABLE		
MOUNTING OPTION	THREAD	THREAD DEPTH
NONE	NONE	NONE
1	M3 X 0.5	6.5mm MIN.
2	#6-32 UNC	0.25" MIN.
3	M3 X 0.5	6.5mm MIN.
4	#6-32 UNC	0.25" MIN.