

FPC 20/40/13 7035**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

Medium-sized polycarbonate enclosures

The FPC series of enclosures is the next generation of the MPC series. Exhibiting the same material properties, the FPC series has an even wider range of accessories and hence extends the number of potential applications.

Features:

- 6 sizes in 2 versions
- Grey or transparent cover
- Cover with lead-seal holes
- Fixing holes outside the sealed area
- Thread for fitting to terminal rails, mounting plates and PCBs
- Comprehensive accessories Weidmüller can manufacture and supply the enclosures to match customer specifications, fitted with all necessary terminals and cable glands.

General ordering data

Version	FPC (polycarbonate empty enclosure), Empty enclosure, Height: 200 mm, Width: 400 mm, Depth: 132 mm, Material: Polycarbonate, untreated, Light Grey
Order No.	9535730000
Type	FPC 20/40/13 7035
GTIN (EAN)	4032248009831
Qty.	1 pc(s).

FPC 20/40/13 7035

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	132 mm	Depth (inches)	5.197 inch
Height	200 mm	Height (inches)	7.874 inch
Width	400 mm	Width (inches)	15.748 inch
Net weight	2,000 g		

Temperatures

Operating temperature	-50 °C...130 °C
-----------------------	-----------------

Cable glands, right

M12	20	M16	11
M20	6	M25	4
M32	2	M40	1
M50	1	M63	1

Cable glands, top/bottom

M12	56	M16	30
M20	18	M25	12
M32	5	M40	4
M50	4	M63	3

Certificate numbers enclosure

Declaration of Conformity No. (DoC LVD)	DE PS2420 220224 003ISS00
---	------------------------------

General information

Access opening: height	196.5 mm	Access opening: width	396.5 mm
Areas of use	Building systems and technology, Transportation, Packaging industry, Machine construction	Enclosure attachment	
Flange plate	No	Impact resistance	Holes 7.5 mm IK08
Integral fixing	thanks to self-tapping screws	Lid	Yes
Lid attachment	4 polyamide crosshead screws	Material	Polycarbonate
Material thickness	3.5 mm	Number of lid screws	4
Operating temperature, max.	130 °C	Operating temperature, min.	-50 °C
Protection degree	IP66, IP67	Seal material	Polyurethane
Surface finish	untreated	Torque for lid screws	0.8 Nm

horizontal assembly

WDU 10 / ZDU 10	1x30	WDU 16 / ZDU 16	1x25
WDU 2,5 / ZDU 2,5 / IDU 2,5	1x59	WDU 35 / ZDU 35	1x19
WDU 4 / ZDU 4	1x49	WDU 6 / ZDU 6	1x37

FPC 20/40/13 7035

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

vertical assembly

WDU 10 / ZDU 10	3x10	WDU 16 / ZDU 16	3x8
WDU 2,5 / ZDU 2,5 / IDU 2,5	3x20	WDU 35 / ZDU 35	3x6
WDU 4 / ZDU 4	3x17	WDU 6 / ZDU 6	3x13

Classifications

ETIM 6.0	EC000261	ETIM 7.0	EC000261
ETIM 8.0	EC000261	ETIM 9.0	EC000261
ETIM 10.0	EC000261	ECLASS 9.0	27-18-01-01
ECLASS 9.1	27-18-92-90	ECLASS 10.0	27-18-01-01
ECLASS 11.0	27-18-01-01	ECLASS 12.0	27-18-01-01
ECLASS 13.0	27-18-01-01	ECLASS 14.0	27-18-01-01
ECLASS 15.0	27-18-01-01		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

ROHS	Conform
------	---------

Downloads


Approval/Certificate/Document of Conformity	DoC Declaration of Conformity LVD - FPC Empty Enclosures - DE PS2420 220224 003ISS00
Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	

FPC 20/40/13 7035

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

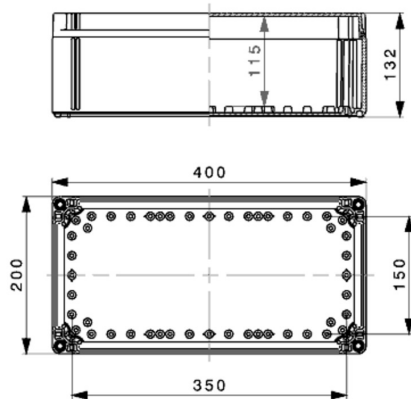

FPC 20/40/13 7035

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

External fixing lugs

External attachment lugs 4-part set



General ordering data

Type	MF FPC	Version
Order No.	9536040000	FPC (polycarbonate empty enclosure), Mounting foot, Fixing lugs,
GTIN (EAN)	4032248009442	Height: 40 mm, Width: 19 mm, Depth: 35.5 mm, Material: Polyamide,
Qty.	1 pc(s).	Light Grey

Ventilation plugs - DAE



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	DAE M12 SS	Version
Order No.	1868550000	DAE (ventilation element), Compensating element, straight, M 12, 10
GTIN (EAN)	4032248440405	mm, IP66, IP68, IP69K, Stainless steel 1.4305 (303)
Qty.	10 pc(s).	
Type	DAE M12 PA LONG	Version
Order No.	1868570000	DAE (ventilation element), Compensating element, straight, M 12, 10
GTIN (EAN)	4032248440429	mm, IP66, IP68, IP69K, Polyamide 6
Qty.	10 pc(s).	

FPC 20/40/13 7035

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

TS 35

Accessories



General ordering data

Type	TS35X7.5 ST FPC 40 HOR	Version
Order No.	8000037560	Rail, TS 35, TS 35 x 7.5, Width: 365 mm, with slot, without slot, Steel,
GTIN (EAN)	4050118653243	galvanized, chromium-plated
Qty.	20 pc(s).	
Type	TS35X7.5 ST FPC 20 VER	Version
Order No.	8000037558	Rail, TS 35, TS 35 x 7.5, Width: 165 mm, with slot, without slot, Steel,
GTIN (EAN)	4050118653229	galvanized, chromium-plated
Qty.	20 pc(s).	

Earthing stud

Earthing bolts to exchange as a complete component in two versions – brass and stainless steel.



General ordering data

Type	PEBZ M6 BR SET	Version
Order No.	1277250000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067149	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Brass
Type	PEBZ M10 BR SET	Version
Order No.	1277220000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067019	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Brass
Type	PEBZ M10 S4 SET	Version
Order No.	1283440000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073362	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)
Type	PEBZ M6 S4 SET	Version
Order No.	1283430000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073607	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)

Creation date May 23, 2025 9:01:03 AM CEST

Catalogue status 10.05.2025 / We reserve the right to make technical changes.

FPC 20/40/13 7035**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****FPC**

Mounting plates, 1.5 mm sheet steel, galvanised

**General ordering data**

Type	MP FPC 20/40	Version
Order No.	9535940000	FPC (polycarbonate empty enclosure), Mounting plate, Mounting
GTIN (EAN)	4032248009664	plate, Height: 160 mm, Width: 360 mm, Depth: 1.5 mm, Material:
Qty.	1 pc(s).	Sheet steel, galvanized, silver

Hinge

MPC series, hinges, set of 2

**General ordering data**

Type	HG FPC	Version
Order No.	9535990000	FPC (polycarbonate empty enclosure), External joint, Hinge, Height: 40
GTIN (EAN)	4032248009701	mm, Width: 50 mm, Depth: 16.5 mm, Material: Plastic, Light Grey
Qty.	1 pc(s).	

FPC 20/40/13 7035**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****TS 15**

Accessories

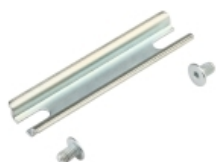**General ordering data**

Type	TS15X5 ST FPC 20 VER	Version
Order No.	8000037604	Rail, TS 15, Width: 235 mm, without slot, Steel, galvanized, chromium-plated
GTIN (EAN)	4050118653168	
Qty.	20 pc(s).	