




Part Number : [2005290051](#)

Product Description : Easy-On FFC/FPC Connector, 1.00mm Pitch, 1.90mm Height, Single Bottom Contact (FS19), Right-Angle, Surface Mount, ZIF, 5 Circuits, Tin-Bismuth Plating

Series Number : 200529

Status : Active

Product Category : FFC / FPC Connectors

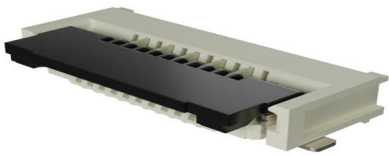

Documents and Resources

Drawings

[2005290051_sd.pdf](#)

[2005290051_stp.zip](#)

[2005290051.dxf](#)

Specifications

[2005299200-SPK-200.pdf](#)

[2005290002-PS-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	200529
Description	Easy-On FFC/FPC Connector, 1.00mm Pitch, 1.90mm Height, Single Bottom Contact (FS19), Right-Angle, Surface Mount, ZIF, 5 Circuits, Tin-Bismuth Plating
Comments	Black Actuator
Product Name	Easy-On
UPC	198282509332

Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	125V

Physical

Actuator Type	Front Flip
Circuits (Loaded)	5
Color - Resin	Beige
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	1.90mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin-Bismuth

Material - Plating Termination	Tin-Bismuth
Material - Resin	Liquid Crystal Polymer (LCP)
Net Weight	95.398/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	No
Pitch - Mating Interface	1.00mm
Pitch - Termination Interface	1.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

Mates With / Use With

Mates with Part(s)

Description	Part Number
1.00mm Pitch Premo-Flex FFC Jumper	<u>15467</u>
1.00mm Pitch Premo-Flex FFC Jumpers	<u>15167</u>
1.00mm Pitch Premo-Flex FFC Jumpers	<u>15267</u>
1.00mm Pitch Premo-Flex FFC Jumpers	<u>98267</u>

This document was generated on Jun 10, 2026