

Honeywell Sensing and Control

Search



4TP1-3

(Home : Products : Switches » MICRO SWITCH™ Rocker Switches » Power-duty Rocker Switches » TP)

narrow your search

Products

- Controls Monitoring and Lighting (286)
- Machine Safety (1727)
- Sensors (6158)
- Switches (9781)
- Wireless (45)

Technology

- Control and Instrumentation (890)
- Electromechanical (9303)
- Magnetic (538)
- Platinum thin film (56)
- Thick Film (1372)
- More...

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



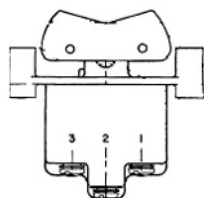
Wireless Web Site
WGLA and WPMM
XYR6000™

[find out more](#)

white papers

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters

Need help?

[Click here to contact us](#)

TP Series Rocker Switch, 4 pole, 2 position, Screw terminal, Flush Panel Mounting

Actual product appearance may vary.

[Sales & Service](#)[Distributor Inventory](#)[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

Product Specifications

Product Type	MICRO SWITCH™ Rocker										
Contact Type	Silver Cadmium Oxide Contacts										
Circuitry	4PDT										
Action	2 position										
Circuitry/Operating action	<table><thead><tr><th>Keyway Position</th><th>Opposite Keyway Position</th></tr></thead><tbody><tr><td></td><td></td></tr><tr><td></td><td></td></tr><tr><td></td><td></td></tr><tr><td></td><td></td></tr></tbody></table>	Keyway Position	Opposite Keyway Position								
Keyway Position	Opposite Keyway Position										
Mounting	Flush Panel										
Lamp Type	Translucent										
Termination	Screw										
Ampere/Voltage Range (Resistive Load)	0.75 A at 115 Vdc, 0.5 A at 250 Vdc, 0.5 A to 15 A at 0.5 Vac to 277 Vac, 0.5 A to 20 A at 0.5 Vdc to 28 Vdc										
LED/Lamp/Neon Voltage	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"										
Comment	Silver cadmium oxide contacts										
Availability	Global										
UNSPSC Code	302119										
UNSPSC Commodity	302119 Switches and controls and relays										
Series Name	TP										

contacts

Customer Service
Technical Support
Global Sales & Service
View Site Demo
Site Comments?

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.

Meet Dr. Larry



my links

Login to iCOM
Login to Rep/AD Portal
Login to Digital University

News Center

HONEYWELL INTRODUCES TRUSTABILITY® NSC SERIES, UNCOMPENSATED / UNAMPLIFIED BOARD MOUNT PRESSURE SENSORS

HONEYWELL EXPANDS ITS LIMITLESS™ PLATFORM WITH THE LAUNCH OF ITS GLOBALLY AVAILABLE INDUSTRIAL WIRELESS RECEIVER

HONEYWELL EXTENDS ITS TRUSTABILITY® PRESSURE SENSOR PRODUCT LINE WITH A SINGLE SIDE LIQUID MEDIA OPTION

MICRO SWITCH
Anniversary site