


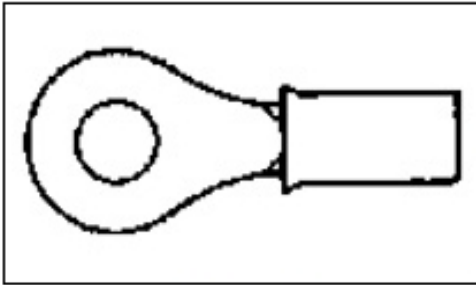

Our commitment. Your advantage.

 [Products](#) [Documentation](#) [Resources](#) [My Account](#) [Customer Support](#)[Home](#) > [Products](#) > [By Type](#) > [Product Feature Selector](#) > Product Details

151435 Product Details

[Live Product Chat](#)**151435**

TE Internal Number: 151435

**Superseded**[Search for Replacement Parts](#)

Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = PIDG
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- [AEROSPACE & DEFENSE](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Body Style](#) = PIDG
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 0.90-1.90 [.035-.075]
- [Stud Diameter \(mm \[in\]\)](#) = 2.36 [0.093]
- Stud Size = 8
- [Shape](#) = RING-041
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin
- Color = Black
- Used For = Thin Wall Cables

Electrical Characteristics:

- Voltage (VAC) = 300

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.20-0.40² [24-22]
- Insulation Sleeve Material = Nylon

Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Temperature Range (°C) = 105

Packaging Related Features:

- [Packaging Method](#) = Loose Piece

Other:

- Brand = AMP

151435-1

[Provide Website Feedback](#) | [Need Help?](#)[Home](#) | [Customer Support](#) | [Suppliers](#) | [Site Map](#) | [Privacy Policy](#) | [Browser Support](#)

© 2009 Tyco Electronics Corporation All Rights Reserved