




+ CONNECTORS
RF CONNECTORS

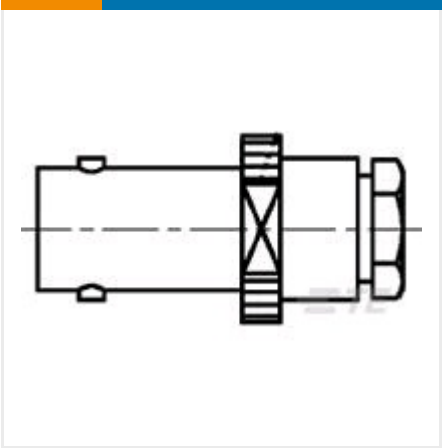

✓ Active

TE CONNECTIVITY (TE)
BNC Str Jk PS 50Ohm Silver Pltd RG58C/U,
[Miniature Coax](#) | [STA](#) , [U](#)

[1-1478409-0](#)
TE Internal Number: 1-1478409-0

[EU RoHS Compliant with Exemptions](#)
[EU ELV Compliant with Exemptions](#)

Connector Interface BNC

Connector Style Jack

Mated Outer Diameter (Approximate) 14.529 mm [.572 in]

Impedance (Ω) 50

Cable Type Raychem 5021D1331, Raychem 5021D1831, Raychem 5021M1631, Raychem EPD 71169Q, RG 188A, RG 316, RG 58C, URM 95

 **PRODUCT DRAWING**
[English](#)

DOCUMENTATION

Product Drawings

BNC STRAIGHT JACK SOLDER(PS) RG58 50 OHM

PDF

English

Instruction Sheets

Instruction Sheet (non U.S.)

GREENPAR RF CONNECTOR CABLE ASSEMBLY INSTRUCTION SHEET

PDF

English

GREENPAR RF CONNECTOR CABLE ASSEMBLY INSTRUCTION SHEET

TIF

English

FEATURES

+

Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Interface BNC

Connector Style Jack

Sealable No

Connector & Contact Terminates To Wire & Cable

Configuration Features

Number of Positions 1

Electrical Characteristics

Impedance (Ω) 50

Body Features

Cable Connector Orientation Straight

Body Material Brass

Body Plating Material Silver

Contact Features

Center Contact Plating Material Silver

Center Contact Material Brass

Termination Features

Termination Method to Wire & Cable Solder/Clamp

Dimensions

Mated Outer Diameter (Approximate) 14.529 mm [.572 in]

Usage Conditions

Cable Type Raychem 5021D1331, Raychem 5021D1831, Raychem 5021M1631, Raychem EPD 71169Q, RG 188A, RG 316, RG 58C, URM 95

Operation/Application

Operating Frequency (GHz) 4

Packaging Features

Packaging Method Bag

Packaging Quantity 50

Other

Dielectric Material PTFE

Gasket Material Silicone Rubber

Grade Professional

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF

