

PPC-157T

15" Panel PC with Intel® Core™2 Duo Processor



Features

- Intel® Core™2 Duo processor up to 2.16 GHz
- System memory up to 4 GB 667 MHz DDR2 SODIMM socket x 2
- One PCIe Expansion Slot (PCI is available as an option)
- One Mini PCI socket, One Mini PCIe socket
- Built-in CF card interface (IDE interface for OS booting)
- Dual Gigabit Ethernet ports supporting LAN teaming
- One RS-232/ GPIO (8 channels, TTL level); (by swapping pin header)
- One RS-232/422/485; (supporting Auto-flow control, selecting by BIOS)



Introduction


The PPC-157T is an Intel Core 2 Duo based Panel PC with 15" color TFT LCD. It features multimedia devices, various connectors, and can be installed in virtually any application. In addition, its user-friendly interface makes it a great host for information appliances. Four serial ports and two Gigabit Ethernet ports give the PPC-157T advanced networking capabilities, and provide a great solution for versatile applications.

Specifications

Processor System	CPU	Supports mSocket 478 based Core 2 Duo up to 2.16 GHz
	CPU FSB	533/667 MHz
	Chipset	945GME + ICH7M
	Disk Drive Housing	Room for 1 x 2.5" SATA HDD
	Dimensions (W x H x D)	396.5 x 317.6 x 103.5 mm (15.6" x 12.5 x 4.08")
	Weight	6 kg (13.22lb)
	Front Panel Protection	IP65 compliant
	HDD	SATA HDD interface (2.5" HDD bay)
	DVD+/-RW Drive	Optional SATA 8X or above DVD+/-RW Drive, Optional optical drive bay
	Memory	Supports up to 4 GB of 667 MHz DDR2 SODIMM system memory (socket x 2)
Network (LAN)	2 x Gigabit Ethernet ports, Wake on LAN, boot from LAN and LAN teaming supported	
	- 4 x COM ports: 2 x RS-232, 1 x RS-232/422/485,	- 2 x Gigabit Ethernet ports
	1 x RS-232/ GPIO (8 channels, TTL level)*	- 1 x D-SUB VGA port
I/O Ports	- 4 x USB 2.0 ports	- 1 x PS/2 mouse and keyboard interface
	- Mic in/ Line out / Line in, 1W speaker	
	* RS-232/422/485 - selecting by BIOS and supporting Auto-flow control, RS-232/GPIO - by swapping pin header	
Bus Expansion	1 x PCI-e Expansion Slot (PCI is available as an option), 1 x Mini PCI socket, 1 x Mini PCI-e socket	
OS Support	OS support	Win XPE / Win XP Pro / WES7 32 & 64 bit / Windows 7 32 & 64 bit (64 bit only for T7400)
Environmental Specifications	Operating Temperature	0 ~ 50° C (32 ~ 122° F)
	Relative Humidity	10 ~ 95% @ 40° C non-condensing
	Shock	Operating 10 G peak acceleration (11 ms duration), follows IEC 60068-2-27
	Vibration	Operating Random Vibration Test 5~500Hz, 1Grms, follows IEC 60068-2-64
	EMC	BSMI, CE, FCC Class B, CCC
	Safety	CB, CE, UL
Power Supply	AC Model	
	Output Rating	150 W (max.)
	Input Voltage	100 ~ 240 V _{ac} , 50 ~ 60 Hz, 2 ~ 4 A
LCD Display	Output Voltage	+3.3 V @ 4.5 A, +5 V @ 8.5 A, +12 V @ 7.0 A, +5 Vsb @ 1.5 A, -12 V @ 0.3 A
	Display Type	Color TFT LCD
	Size (Diagonal)	15"
	Max. Resolution	1024 x 768
	Max. Colors or Grayscale	262K
	Pixel Pitch (mm)	0.297 x 0.297
	Luminance (cd/m ²)	350
	Contrast Ratio	400:1
	Viewing Angle	80° (left), 80° (right), 70° (up), 60° (down)
	LCD MTBF	50,000 hrs
Touchscreen (optional)	Type	5-wire Analog Resistive (USB interface)

Dimensions

Unit: mm

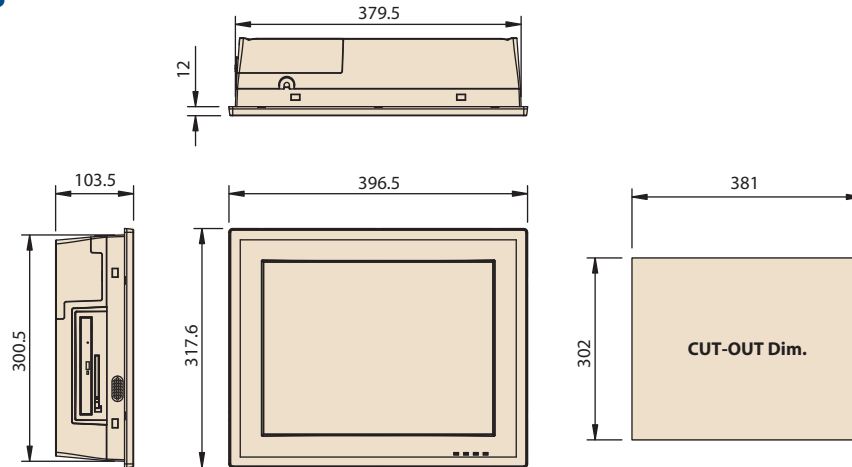

Ordering Information

Part No.	Description
PPC-157T-BAREE	15" C2D Based PPC without T/S
PPC-157T-BARE-TE	15" C2D Based PPC with Resistive T/S
PPC-155T STAND	Stand kit for PPC-155/157/175/177 series
PPC-ARM-A03	PPC ARM VESA Standard
PPC-174T-WL-MTE	Wall mount kit for PPC series
1702002605	Power cord 90D 220V EUROPEAN 250V/6A, 1.8M
1702002600	Power cord UL/CSA (USA) 180D 125V/10A 1.83M
989K017700E	Optical disc drive kit for PPC-157/177 (W/O ODD)
989K017702E	DVD-RW (SATA) module for PPC-157/177
989K070601E	PCI riser card for PPC-157/177
989KP15503E	Purchase 802.11a/b/g Mini-PCI Wireless Module for PPC-157/177
2070011562	XPE WES2009 V4.3, 24 multi-language with SUSI Access

Feature Details


Protection

To meet the requirements of a public environment, the front panel PPC-157T complies with the IP65 protection standard. Furthermore, the watchdog timer and power management features make the system secure and stable. The onboard hardware monitoring feature provides an automatic protection function, which prevents the CPU from becoming overheated.

Expansion

To extend functionality, the PPC-157T is designed with one PCI-e expansion Slot (PCI is available as option) and Four USB 2.0 (Universal Serial Bus) ports. With these expansion capabilities, the PPC-157T not only functions as an HMI, but also as a computing center on which to build your applications.

I/O Appearance

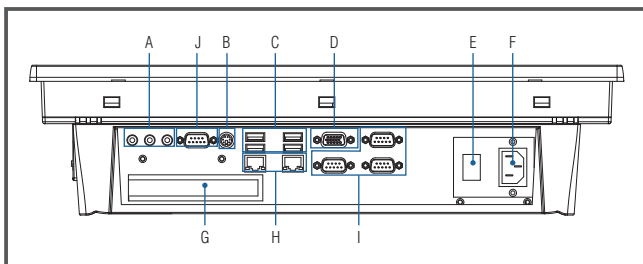

- | | |
|----------------------------|---|
| A: Line in/Line out/Mic in | F: AC Inlet |
| B: PS2 Mouse & Keyboard | G: PCI Slot x 1 |
| C: USB 2.0 x 4 | H: 10/100/1000 Base-T Ethernet x 2 |
| D: VGA Port | I: RS-232 x 3 (including RS232/422/485 x 1, COM2) |
| E: Power Switch | J: RS-232/GPIO (by swapping pin header) |