
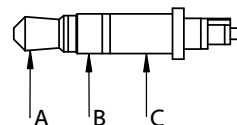


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	NOTES
1	50-00502	Connector, stereo plug, 3.5xL20.5 mm, brass, gold plated, molding style	2	
2	30-00653	Wire, 2C TS, 28 AWG, 150V, 70C, 2.6 mm, spiral shield, TPU, WBL	1	Bio-compatible jacket
3	24-00028	Overmold, TPE, black	2	

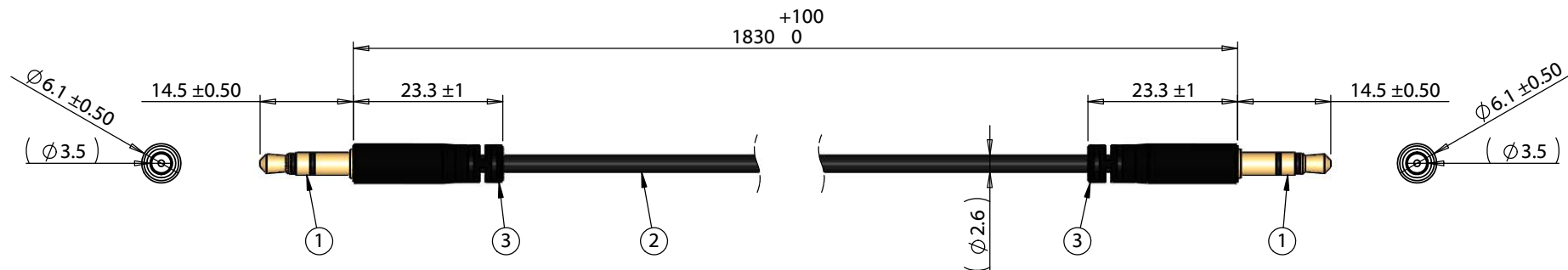

Wiring Diagram		
50-00502	wire color	50-00502
A	white	A
B	black	B
C	shield	C

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com
A	10/20/2015	Initial release	GL	RoHS compliant	
A1	11/11/2015	Modified overmold material	PS	Function test: no open, no short circuit, no intermittent	
A2	01/07/2016	Modified dimensions	Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description: Cable, 1830 mm, 3.5 mm 3C 50-00502 slim audio plug to same, 28 AWG, 30-00653, shielded, WBL	
Size: A Scale: 1:2 Part number: 10-02047					Sheet 1 of 1