

 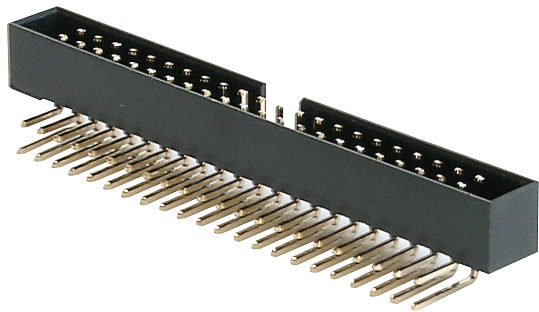


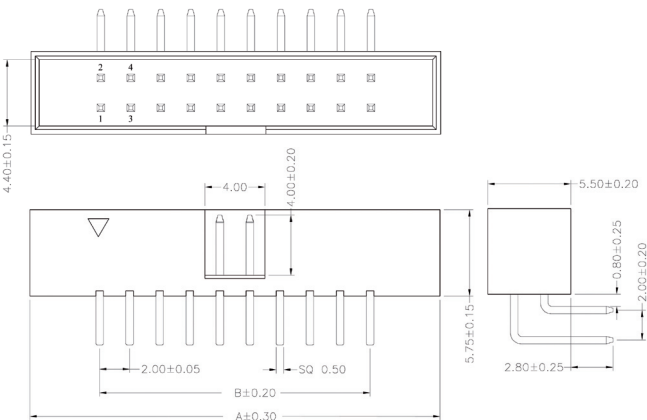

Isolierkörpermaterial
PA6T, UL94V-0
Kontaktmaterial
Messing
Kontaktoberfläche
Ni, Au
Kontaktwiderstand
20mΩ max
Isolationswiderstand
1000MΩ min
Strombelastbarkeit
1.5A
Betriebstemperatur
-40°C - +105°C
Betriebsspannung
125V AC
Prüfspannung
1000V AC
Verpackung
Blisterverpackung

Insulator material
PA6T, UL94V-0
Contact material
Brass
Plating
Ni, Au
Contact resistance
20mΩ max
Insulation resistance
1000MΩ min
Current rating
1.5A
Operating temperature
-40°C to +105°C
Operating voltage
125V AC
Test voltage
1000V AC
Packing
Tray packing

Dimensions		
No. of contacts	A	B
10	17.00	8.00
14	21.00	12.00
16	23.00	14.00
20	27.00	18.00
26	33.00	24.00
34	41.00	32.00
40	47.00	38.00
44	51.00	42.00
50	57.00	48.00



Bestellcode / Ordercode

Polzahl

No. of contacts

10 / 14 / 16 / 20 / 26 /
34 / 40 / 44 / 50

10 / 14 / 16 / 20 / 26 /
34 / 40 / 44 / 50

2 - Gold flash

2 - Gold flash

AWHW2 xx A - 0 2 0 2

Bitte „x“ durch die geeignete Option ersetzen
Please replace „x“ with appropriate option