

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1301540041

Status:


Active

Overview:

Heavy-Duty Industrial Wiring Devices

Description:

Super-Safeway Standard Molded Y Cordset, 12 Gauge, 2 Pole/3 Wire, Cordset Length 0.91m (3.0'), NEMA 6-20, 250V

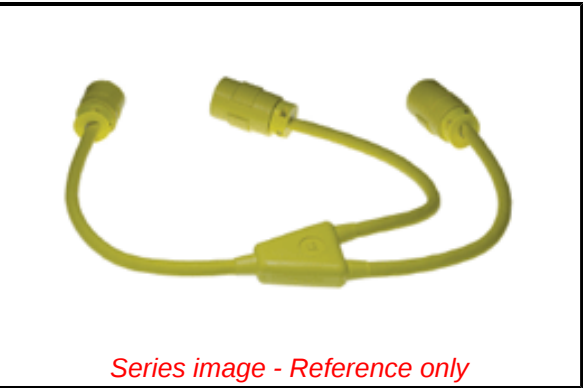

Series image - Reference only

Documents:

Brochure (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Wiring Devices
Series	130154
IP Rating	N/A
NEMA Configuration	NEMA 6-20
Overview	Heavy-Duty Industrial Wiring Devices
Product Name	Super-Safeway
Receptacle Type	Duplex
Specialty	N/A
Type	Molded Y Cordset
UPC	78678899540
Physical	
Flange	No
Flip Lid	No
Gender	Male-Female
Length	0.91m (3.0')
Locking Blade	No
Poles	2-pole/3-wire
Electrical	
Cord Type	12/3 SOOW
Current - Maximum per Contact	20.0A
GFCI	No
Lighted Connector	No
Voltage - Maximum	250V
Material Info	
Engineering Number	1448-Y

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130154 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION