


USB Sound Level Datalogger



Features:

- USB interface for easy setup and data download
- 30 to 130dB range
- Datalogging capability up to 129,920 records
- Selectable data sampling rate
- Records readings with real time clock
- Two start methods: programmed (from PC) or manual
- 0.5" electret microphone
- Includes 3.6V Lithium battery, Windows® compatible software, USB cover, tripod, USB extension cable, and windscreens

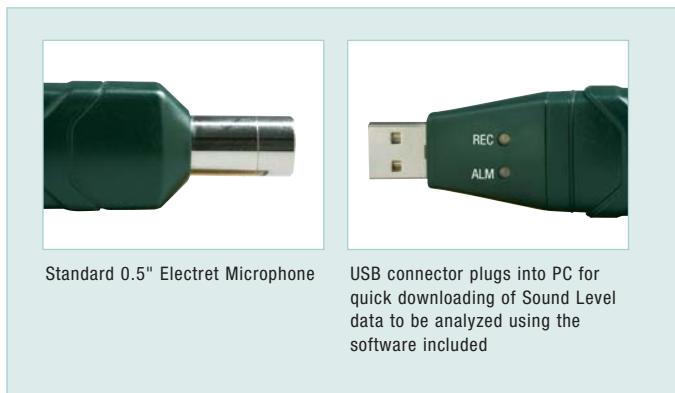

Specifications	
Range	30 to 130dB
Frequency Range	31.5 to 8kHz
Basic accuracy	±1.4dB
Weighting	A and C
Response Time	Fast (125ms)/Slow (1s)
Datalogging	129,920 points
PC Interface	USB
Dimensions	5.1 x 1.1 x 0.9" (130 x 30 x 25mm)
Weight	1oz (20g)

Ordering Information:

407760USB Sound Level Datalogger
 407760-NISTL ..USB Sound Level Datalogger with NIST Certificate (single point)
 422993.6V Lithium Battery (pkg of 2)

