

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0733910070

Status:

Active

Overview:

SMA RF Connectors

Description:

50 Ohms, SMA PCB Jack Receptacle, Vertical, with Standoffs, 80 Pieces Per Tray

Documents:

3D Model (PDF)

3D Model

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Overview

Product Name

Style

Taxonomy

Type

UPC

Wire/Cable Type

RF/Coax Connectors

73391

SMA RF Connectors

SMA

PCB

RF / Coaxial Connectors

Subminiature

800753926158

N/A

Physical

Gender

Keying to Mating Part

Net Weight

Orientation

PCB Mounting

PCB Thickness - Recommended

Packaging Type

Panel Mount

Panel Mount Method

Reverse Polar

Jack

None

1.474/g

Straight

Through Hole

3.00mm

Tray

No

N/A

No

Electrical

Frequency

Impedance

Power / Voltage

18 GHz

50Ω

VOLTAGE: 500 Vrms@Sea Level

Solder Process Data

Duration at Max. Process Temperature (seconds)

Lead-freeProcess Capability

Max. Cycles at Max. Process Temperature

Process Temperature max. C

010

SMC&WAVE

002


260

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-73391-007-001

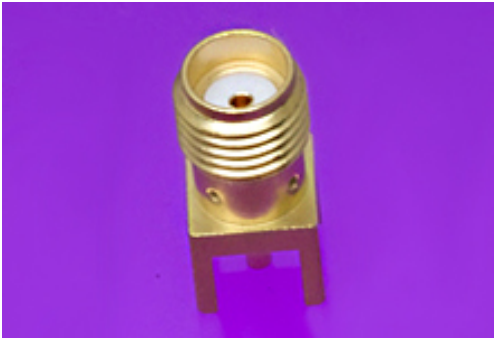

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

73391 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION