


03 038399

Circular connectors with threaded joint M16 acc. to IEC 61076-2-106, IP40/IP68



Protecting cap, IP68, for plugs, without chain

03 038399

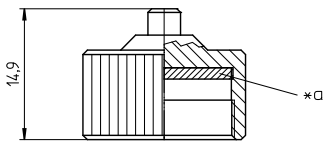

*a flat gasket

Environmental conditions

Temperature range -40 °C/+85 °C

Materials

Cap	CuZn, nickel-plated
Seal	CR
Chain	CuZn, pre-nickel and verchromt

Mechanical data

Tightening torque connector	1-3 Nm
Tightening torque nut	1-3 Nm
Protection class	IP68 ¹

¹ according to IEC DIN EN 60529, only in locked condition with an appropriate counterpart; IPX8 requirements under agreement between manufacturer and user

Associated products

Accessories

☞ 0314	☞ 0314-1	☞ 0314-2
☞ 0315	☞ 0315-1	☞ 0315-1 U
☞ 0315-2	☞ 0316	☞ 0316-1
☞ 0316-2	☞ 0317	☞ 0317-1
☞ 0317-2	☞ 031798-1	☞ 031798-2
☞ 031799-2	☞ 0318	☞ 0318-1
☞ 0318-2	☞ 0331	☞ 0332
☞ 0332-1	☞ 033200	☞ 0365
☞ 036500	☞ SFV	☞ SFV ... C
☞ SGR	☞ SGV	☞ SGV ... C
☞ SV	☞ SV ... C	☞ SV ...-8
☞ SV ...-8 C	☞ WSV	☞ WSV ... C
☞ Weitere Produkte auf Anfrage	☞ Weitere Produkte auf Anfrage	

03

038399

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
038399	-	50	100

Packaging:

in a cardboard box