




Part Number : [526100672](#)

Product Description : Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 6 Circuits, Gold Plating

Series Number : 52610

Status : Active

Product Category : FFC / FPC Connectors

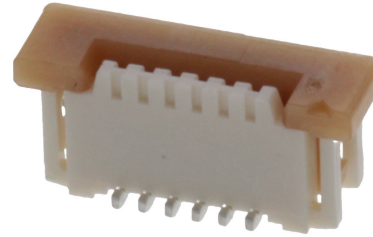

Documents & Resources

Drawings

[Drawing 526100672_sd.pdf](#)

3D Models and Design Files

[2D Drawing DXF 526100672.dxf](#)

[2D Drawing DXF \(PDF\) 526100672.pdf](#)

[3D Model 526100672_stp.zip](#)

Specifications

[Packaging Specification SPK-52610-003-001.pdf](#)

[Product Specification PS-52610-007-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	52610
Description	Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 6 Circuits, Gold Plating
Series Name	Slider
Product Family	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	822350225922

Agency

CSA	LR19980
UL	E29179

Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	125V

Physical

Actuator Type	Slider
Circuits (Loaded)	6
Circuits (maximum)	6
Color - Resin	Natural
Contact Position	N/A
Durability (mating cycles max)	30

Flammability	94V-0
Mated Height	5.75mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	373.458/mg
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PC Tail Length	2.00mm
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	None
Pitch - Mating Interface	1.00mm
Pitch - Termination Interface	1.00mm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

Mates With / Use With

Mates with Part(s)

Description	Part Number
1.00mm Pitch Premo-Flex FFC Jumpers	<u>15039</u>

This document was generated on Sep 22, 2024