

Honeywell Sensing and Control

Search



4TL1-12P

(Home : Products : Switches » MICRO SWITCH™ Toggle Switches » TL)

narrow your search

Products

- Controls Monitoring and Lighting (286)
- Machine Safety (1727)
- Sensors (6158)
- Switches (9781)
- Wireless (45)

Technology

- Control and Instrumentation (890)
- Electromechanical (9303)
- Magnetic (538)
- Platinum thin film (56)
- Thick Film (1372)
- More...

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



 
Wireless Web Site
WGLA and WPMM
XYR6000™

[find out more](#)

white papers

Wireless Switches Offer
Unlimited Benefit
Basic Switches Are Not Created
Equal
Applying Precision Switches
Sensors for Medical Devices
New Ways to Measure Torque
Choosing Safety Switches
Specifying Hour Meters

Need help?

[Click here to contact us](#)


Actual product
appearance
may vary.

TL Series Toggle Switch, 4 pole, 3 position, Screw terminal, Locking
Lever, Military Part Number MS27409-1P

Overview Specs Documentation Application Notes

Product Specifications

Circuitry/Operating
action

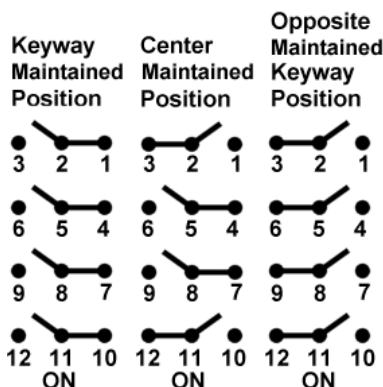

Product Type
Lever Lock

MICRO SWITCH™ Toggle Switch



Locked out of
and into
extreme position
(Keyway side)

Ampere/Voltage Range (Resistive Load)	0.5 A to 20 A at 0.5 Vdc to 28 Vdc, 0.75 A at 115 Vdc, 0.5 A to 15 A at 0.5 Vac to 277 Vac, 0.5 A at 250 Vdc
Circuitry	4PDT
Action	3 position
Mounting	Bushing 15/32 in
Termination	Screw
MIL Spec. Number	MS27409-1P
Lever Type	Locking
UL/CSA	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"
Comment	Silver cadmium oxide contacts
Availability	Global
UNSPSC Code	30211908
UNSPSC Commodity	30211908 Toggle switches
Series Name	TL

contacts

Customer Service
Technical Support
Global Sales & Service
View Site Demo
Site Comments?

meet dr. larry

VIDEO - Dr. Larry
Goldstein explains our
newest and best
technologies.

Meet Dr. Larry



my links

Login to iCOM
Login to Rep/AD Portal
Login to Digital University

News Center

HONEYWELL INTRODUCES
TRUSTABILITY® NSC SERIES,
UNCOMPENSATED /
UNAMPLIFIED BOARD MOUNT
PRESSURE SENSORS

HONEYWELL EXPANDS ITS
LIMITLESS™ PLATFORM WITH
THE LAUNCH OF ITS GLOBALLY
AVAILABLE INDUSTRIAL
WIRELESS RECEIVER

HONEYWELL EXTENDS ITS
TRUSTABILITY® PRESSURE
SENSOR PRODUCT LINE WITH
A SINGLE SIDE LIQUID MEDIA
OPTION

MICRO SWITCH
Anniversary site