

SKINTOP® GMP-GL

SKINTOP® GMP-GL, glass fibre-reinforced counter nuts, for maximum mechanical stability, for locking in boreholes without thread



Variety of approval certifications



Temperature-resistant



Assembly time

Benefits

Glass fibre-reinforced for maximum mechanical stability

Supporting surface for spanner means scratches on the housing are avoided

Application range

For locking SKINTOP® cable glands in boreholes without thread.

Norm references / Approvals

UL File Nr. E79903

Product Make-up

PG connection thread

Note

UL approval only when used with the UL-approved SKINTOP® polyamide cable glands

Designed for use with SKINTOP® ST(R)

Last Update (28.10.2018)

©2018 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SKINTOP® GMP-GL

Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC000441 ETIM 5.0 Class-Description: Cable screw gland
Classification ETIM 6:	ETIM 6.0 Class-ID: EC000441 ETIM 6.0 Class-Description: Cable screw gland
On request:	Available without collar (without surface for assembling tool)
Colour delivered:	Silver grey (RAL 7001) Light grey (RAL 7035) Black (RAL 9005), UV-resistant
Material:	Polyamide, glass fibre-reinforced
Temperature range:	-20°C to +100°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

SKINTOP® GMP-GL

Article number	Article designation / size	SW wrench size mm
SKINTOP® GMP-GL silver grey with collar		
53019000	PG 7	19
53019010	PG 9	22
53019020	PG 11	24
53019030	PG 13,5	27
53019040	PG 16	30
53019050	PG 21	36
53019060	PG 29	46
53019070	PG 36	60
53019080	PG 42	65
53019090	PG 48	70
SKINTOP® GMP-GL black with collar		
53019200	PG 7	19
53019210	PG 9	22
53019220	PG 11	24
53019230	PG 13,5	27
53019240	PG 16	30
53019250	PG 21	36
53019260	PG 29	46
53019270	PG 36	60
53019280	PG 42	65
53019290	PG 48	70
SKINTOP® GMP-GL light grey with collar		
53019001	PG 7	19
53019011	PG 9	22
53019021	PG 11	24
53019031	PG 13,5	27
53019041	PG 16	30
53019051	PG 21	36
53019061	PG 29	46
53019071	PG 36	60
53019081	PG 42	65
53019091	PG 48	70

Last Update (28.10.2018)


©2018 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SKINTOP® GMP-GL

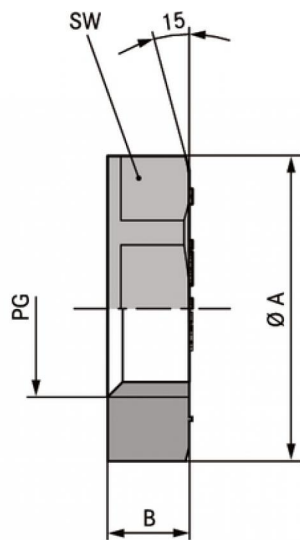

Last Update (28.10.2018)

©2018 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16