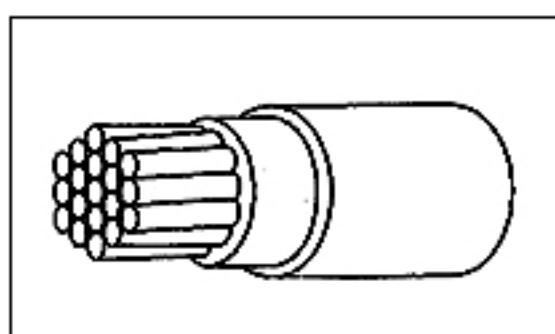


FLT0111-0.25-0 Product Details

[!\[\]\(e3f8612927870f2e0f9f5989e6dd3064_img.jpg\) Share](#) [!\[\]\(a86c7d1c9cb81c81614634a31267440d_img.jpg\) Print](#) [!\[\]\(ce158fc5e55633398941d0898ae45661_img.jpg\) Email](#)


Commercial Wire

 Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Type = FLT
- Conductor Type = Tin-Plated Copper
- Conductor (Wire) Size = .25mm²
- Temperature Range = -65 - 150 °C
- Color = Black

[View all Features](#)

TE Internal Number: 2723233001

 Active

[!\[\]\(4f6bf54ae7e4144a72d78316053e412d_img.jpg\) Add to My Part List](#) [!\[\]\(1be454ab98bc856a53cc962da77a541d_img.jpg\) Request Sample](#) [!\[\]\(c0149066729715e1f65b56e37efafeee_img.jpg\) Find Similar Products](#) [!\[\]\(44211123bbd9216afa358c226e756ccd_img.jpg\) Buy Product](#)

Quick Links

- [Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [Customer Drawing \(PDF, English\)](#)

Related Products:

- [Tooling](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Cable Type = FLT](#)
- [Color = Black](#)
- [Cable Style = Primary](#)

Configuration Features:

- [Conductor \(Wire\) Size = .25mm²](#)
- [Number of Conductors = 1](#)
- [Number of Strands x Diameter \(mm \[in\]\) = 19 x 0.127](#)

Electrical Characteristics:

- [Voltage \(VAC\) = 600](#)
- [Resistance, Maximum \(Ω/1000 ft@68°F\) = 83.6](#)

Industry Standards:

- [RoHS/ELV Compliance = RoHS compliant, ELV compliant](#)
- [Lead Free Solder Processes = Not relevant for lead free process](#)
- [RoHS/ELV Compliance History = Always was RoHS compliant](#)

Dimensions:

- [Conductor Diameter Range \(mm \[in\]\) = 0.55 - 0.63 \[0.022 - 0.025\]](#)
- [Cable Diameter Range \(mm \[in\]\) = 0.91 - 1.04 \[0.036 - 0.041\]](#)

Conditions for Usage:

- [Temperature Range \(°C\) = -65 - +150](#)

Body Features:

- [Conductor Type = Tin-Plated Copper](#)
- [Wire Type = Stranded](#)
- [Nominal Weight \(kg/km\) = 2.96](#)

Product Availability:

- [Region = Europe](#)

Other:

- [Brand = Raychem](#)

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

 Enter your email address 
