


Crocodile clips

AGF 1

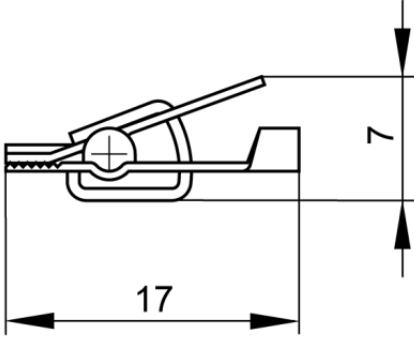

| Product | AGF 1 |
|---|---|
| description | Miniature alligator clip for small components, e.g. on printed circuits. silver-plated surface. Maximum clamping range 1 mm ² . Maximum connecting lead cross-section 0.5 mm ² solder or crimped. |
| operating instruction | BA210 |
| Articlenummer | 930476001 |
| | Ag |
| drawing | |
| |  |
| technical data | |
| connection | solder connection, crimp terminal |
| rated voltage | 30 VAC / 60 VDC |
| measurement cat. acc. to IEC 61010 | O ⁽²⁾ |
| rated current (consider derating curve) | 3 A |
| material socket | brass, silver plated |
| temperature range acc. To IEC61010 ⁽¹⁾ | -25 °C to +100 °C |
| clamping range | 1 mm |

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022