

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210230341](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form A-18mm, PG9 Internal Threads, 3 Pole Plus Ground Terminal, 250V AC/300V DC, Black, NBR Profiled Gasket and Screw, Bulk Pack, Mounted

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-121023-C18-001 \(PDF\)](#)
[Product Specification STR-1552-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Field Attachable / Accessories
Series [121023](#)
Form A - 18mm
IP Rating IP65
Material - Contact Brass
Overview [mPm DIN Valve Connectors](#)
Product Name mPm
Type Field Attachable Connector
UPC 883906248970

Physical

Cable Diameter 6.00-8.00mm
Coupling Type Internal Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polyamide
Material - Coupling Nut N/A
Material - Plating Mating Silver
Net Weight 24.914/g
Orientation 90° Angle
Pitch - Mating Interface 18.00mm
Poles 3
Temperature Range - Operating -40°C to +90°C
Wire Size AWG N/A

Electrical


Current - Maximum per Contact 16.0A
Voltage - Maximum 250V AC / 300V DC

Material Info

Engineering Number C18309N21

Reference - Drawing Numbers

Packaging Specification PK-121023-C18-001
Product Specification STR-1552-001
Sales Drawing 1210230229-000, SD-121023-001-001

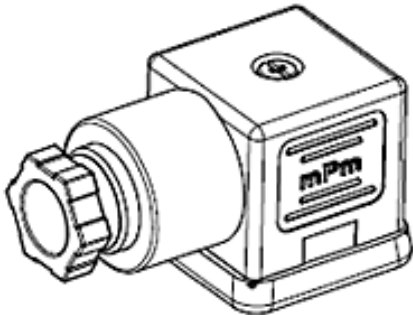

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[121023 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION