


Specification Sheet

Part Number: 151-00669

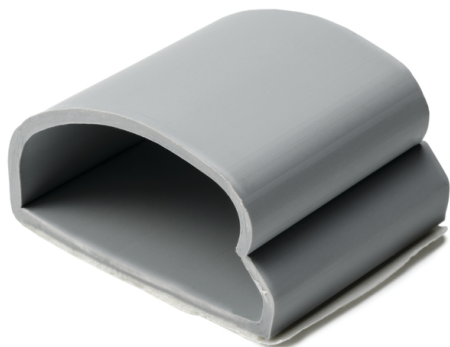

Lead-in angle design allows for quick and easy installation of wires and cables.

Rubber based adhesive allows for a permanent bond to most surfaces.

Article Number	151-00669
----------------	-----------

Type	WAC100
------	--------

Color	Gray (GY)
-------	-----------

Quantity Per	pack
--------------	------

Product Description	The WAC Adhesive cable clamps are designed with lead in angles allowing for easy insertion of wires and cables. The rubber based adhesive allows for a permanent bond to most surfaces. Available in two sizes.
---------------------	---

Short Description	WAC Adhesive Cable Clamp, 1" Max. Bundle Dia, PVC, Gray, 100/pkg
-------------------	--

Global Part Name	WAC100-PVC-GY
------------------	---------------

Length L (Imperial)	1.5
Length L (Metric)	38.1
Width W (Imperial)	1.25
Width W (Metric)	31.8
Bundle Diameter Min (Imperial)	0.75
Bundle Diameter Min (Metric)	19.1
Bundle Diameter Max (Imperial)	1
Bundle Diameter Max (Metric)	25.4
Height H (Imperial)	0.85
Height H (Metric)	21.6
Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
Adhesive	Self adhesive
Flammability	UL 94 V-0 (excluding adhesive)
UV Resistant (Yes/No)	No

Operating Temperature	+122°F (+50°C)
-----------------------	----------------

Reach Compliant (Article 33)	No
------------------------------	----

Package Quantity (Imperial)	100
-----------------------------	-----

Package Quantity (Metric)	100
---------------------------	-----

Customs Number	3926909988
----------------	------------

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)