

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0354301700
Status: Active
Description: 6.00mm Tab Wire-to-Wire Terminal, Female, Two-Piece Type, Wire Range AVC

Documents:

- Drawing (PDF)
- Product Specification PS-35270-001-001 (PDF)
- Product Specification PS-35385-001-001 (PDF)
- Packaging Specification PK-35430-001-001 (PDF)
- RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Application

Crimp Quality Equipment

Product Name

UPC

Crimp Terminals

35430

Power

Yes

N/A

756054281567

Physical

Gender

Material - Metal

Material - Plating Mating

Material - Plating Termination

Net Weight

Packaging Type

Plating min - Mating

Plating min - Termination

Termination Interface: Style

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Female

Copper-Nickel-Tin, High Copper

Tin

Tin

0.946/g

Reel

0.813µm

0.813µm

Crimp or Compression

1.80-2.00mm

20, 22

N/A

Electrical

Current - Maximum per Contact

30.0A

Material Info

Reference - Drawing Numbers

Crimp Specification

Packaging Specification

Product Specification


Sales Drawing

CS-35430-001-001

PK-35430-001-001

PS-35270-001-001, PS-35385-001-001

SD-35430-001

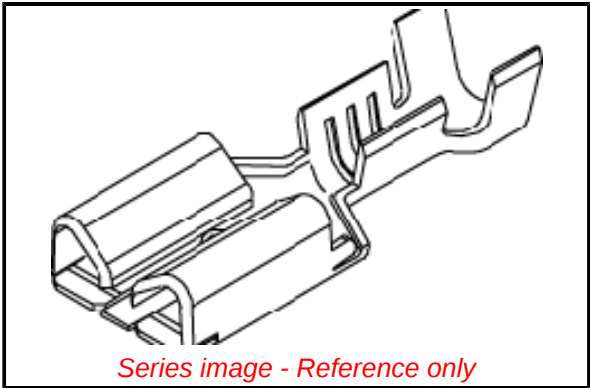

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

35430 Series

Mates With

35725 Terminal

Use With

35270 Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION